


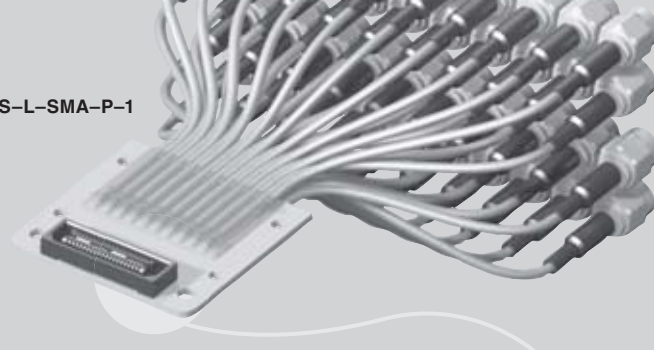

EQRF SERIES

COMBINATION Q SERIES®/RF CABLE

SPECIFICATIONS

For complete specifications see www.samtec.com?EQRF

Connectors:

Q Series®:

See QTE or QSE Series

RF:

See SMA, MCX or MMCX Series

RoHS Compliant:

Yes

RG 178 Cable:

Impedance: 50Ω

Capacitance:

89.61pF/meter

Propagation Delay:

4.83 nsec/meter

Max Attenuation

(cable only):

1.71dB @ 1GHz for 1 meter

Conductor Size:

30 AWG, (0.31mm) .012" dia.

Conductor Material:

Silver Plated Copper

Conductor Resistance:

0.34Ω/meter max

Current Rating: 3A

Insulator Diameter:

(0.86mm) .034"

Insulator Material: PTFE

Dielectric Constant: 2.1dK

Shield Material:

Silver Plated Copper Clad Steel

Jacket Material: FEP

Jacket Diameter:

(1.80mm) .071"

Jacket Temp Rating:

-50°C to +250°C

Jacket Color: Amber

RoHS Compliant:

Yes

RG 316 Cable:

Impedance: 50Ω

Capacitance: 96.432pF/meter

Propagation Delay:

4.83 nsec/meter

Max Attenuation

(cable only):

1.25dB @ 1GHz for 1 meter

Conductor Size:

26 AWG, (0.51mm) .020" dia.

Conductor Material:

Silver Plated Copper

Conductor Resistance:

0.13Ω/meter max

Current Rating: 5A

Insulator Diameter:

(1.52mm) .060"

Insulator Material: PTFE

Dielectric Constant: 2.1dK

Shield Material:

Silver Plated Copper Clad Steel

Jacket Material: FEP

Jacket Diameter:

(2.54mm) .100"

Jacket Temp Rating:

-50°C to +250°C

Jacket Color: Amber

RoHS Compliant:

Yes

Note: Some lengths, styles and options are non-standard, non-returnable.


Mates with:

QTE, QSE,
MMCX, MCX, SMA



Cable Length	EQRF Rated @ 7dB Insertion Loss	
	-DP	-SE
6" (152mm)	4.62 GHz / 9.24 Gbps	4.62 GHz / 9.24 Gbps

Performance data for other cable lengths and complete test data available at www.samtec.com?EQRF or contact sig@samtec.com

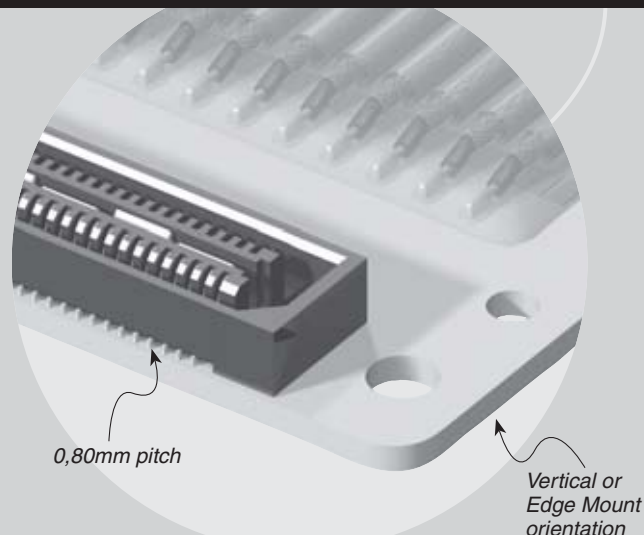

EQRF



NO. OF POSITIONS
PER ROWWIRE
LENGTH

-020, -040
(40 Positions Per Bank)


-“XXXX”
= Wire Length in millimeters
0152mm (06.00") MIN

GENDER/ ORIENTATION	L
-S-S & -S-M	(20,88) .822
-T-S & -T-M	(21,64) .852
-SL & -TL	(17,35) .683
-SR & -TR	


NO. OF POSITIONS	A	B	C	D
40	(39,69) 1.563	(40,61) 1.599	(45,47) 1.790	(50,76) 1.999
80	(65,60) 2.583	(66,52) 2.619	(71,37) 2.810	(76,67) 3.019

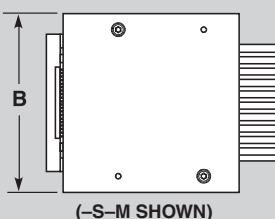 

(-S-M SHOWN)

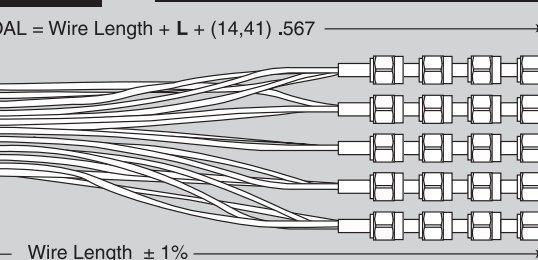

Wire Length ± 1%

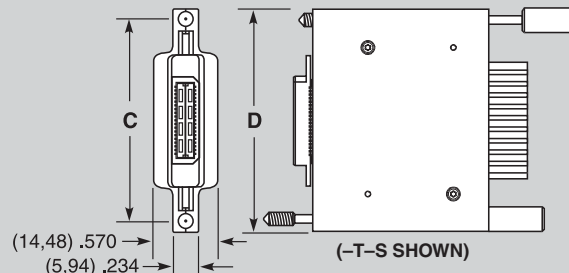


(-T-S SHOWN)


Due to technical progress, all designs, specifications and components are subject to change without notice.

WWW.SAMTEC.COM


SAMTEC USA • Tel: 1-800-SAMTEC-9 or 812-944-6733 SAMTEC NORTHERN CALIFORNIA • Tel: 408-395-5900 SAMTEC SOUTHERN CALIFORNIA • Tel: 1-800-726-8329
SAMTEC AMERICA LATINA COMERCIO EXTERIOR LTDA • Tel: (+55 31) 3786 3227 SAMTEC UNITED KINGDOM • Tel: 44 01236 739292 SAMTEC GERMANY • Tel: +49 (0) 89 / 89460-0
SAMTEC FRANCE • Tel: 33 01 60 95 06 60 SAMTEC ITALY • Tel: 39 039 6890337 SAMTEC NORDIC/BALTIC • Tel: +46-84477280 SAMTEC BENELUX • Tel: 44 01236 739292
SAMTEC ISRAEL • Tel: 972-3-7526600 SAMTEC INDIA • Tel: +91-80-3272 1612 SAMTEC ASIA PACIFIC • Tel: 65 6745-5955 SAMTEC JAPAN • Tel: 045-475-1385 SAMTEC CHINA • Tel: 86-21-6083 3766
2735-6109 SAMTEC HONG KONG • Tel: 852-26904858 SAMTEC KOREA • Tel: 82-31-717-5685 SAMTEC ANZ • Tel: 613 9580 0683

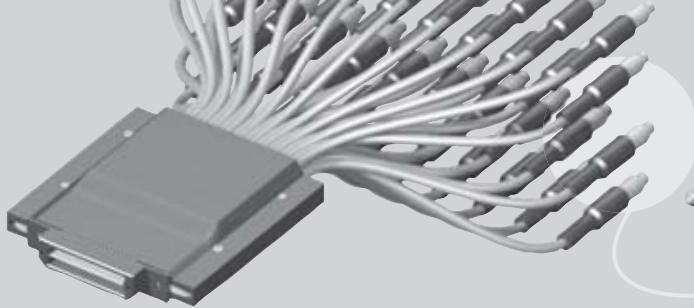

EQR-020-0152-T-M-MMCX-P-1

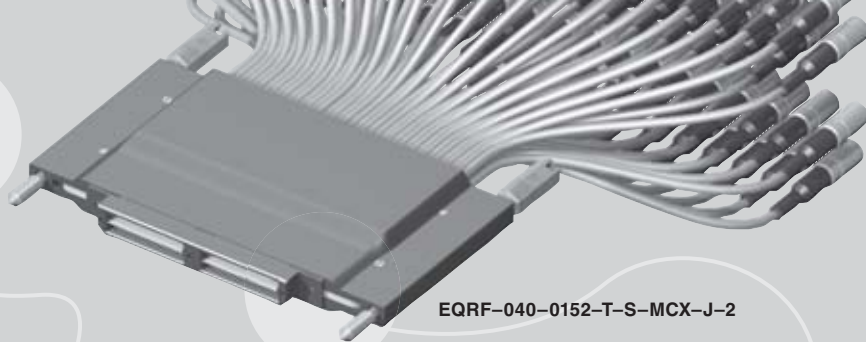


EQR-040-0152-T-S-MCX-J-2

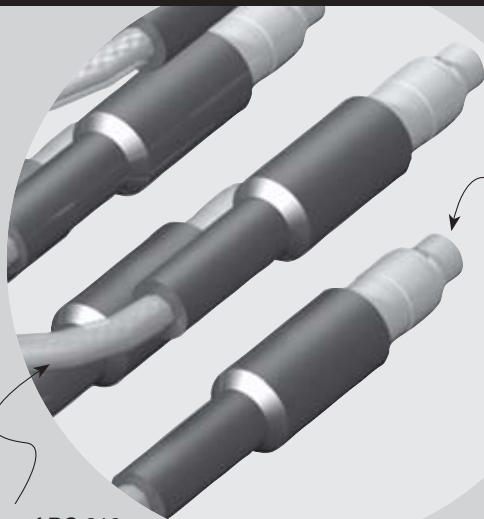

Choice of SMA,
MCX or MMCX
RF termination

Choice of RG 316
or RG 178 cable

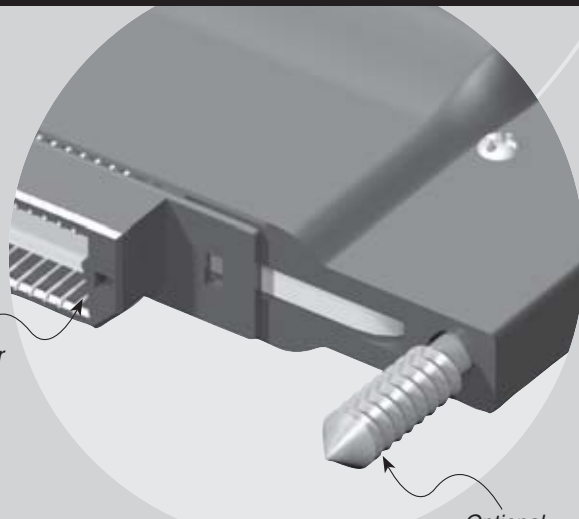

Socket or
Terminal

Optional
Captive Screws

Q SERIES® GENDER

-T
= Terminal
-S
= Socket

Q SERIES® ORIENTATION

-M
= Edge Mount
-S
= Edge Mount with Captive Screws
-R
= Surface Mount, Notch Right
-L
= Surface Mount, Notch Left

RF CONNECTOR

-MMCX
= RF Plug
-MCX
= RF Jack or Plug
-SMA
= RF Jack or Plug




RF GENDER

-P
= Plug
-J
= Jack
(MCX & SMA only)




COAX CABLE

-1
= RG 316
-2
= RG 178
(See RF Connector Type
for Availability)

RG 316 Cable Options

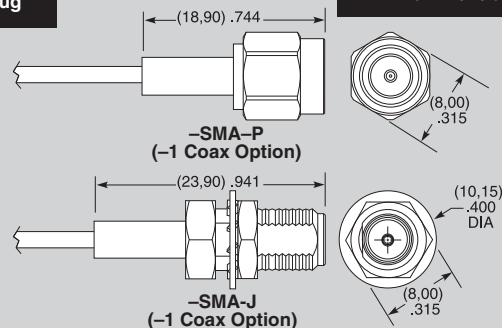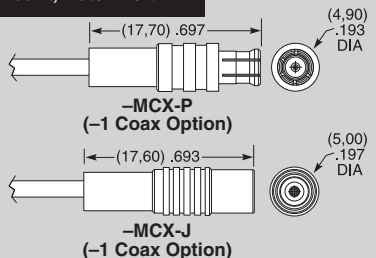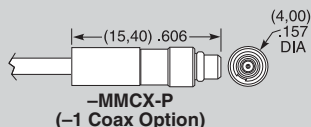

RG 178 Cable Options

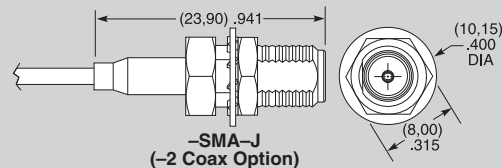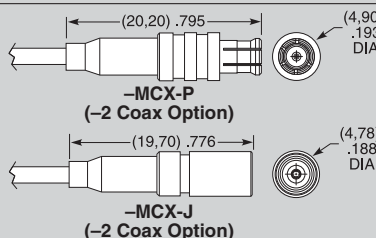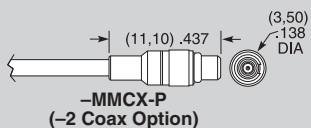

Due to technical progress, all designs, specifications and components are subject to change without notice.

WWW.SAMTEC.COM

SAMTEC USA • Tel: 1-800-SAMTEC-9 or 812-944-6733 SAMTEC NORTHERN CALIFORNIA • Tel: 408-395-5900 SAMTEC SOUTHERN CALIFORNIA • Tel: 1-800-726-8329
SAMTEC AMERICA LATINA COMERCIO EXTERIOR LTDA • Tel: (+55 31) 3786 3227 SAMTEC UNITED KINGDOM • Tel: 44 01236 739292 SAMTEC GERMANY • Tel: +49 (0) 89 / 89460-0
SAMTEC FRANCE • Tel: 33 01 60 95 06 60 SAMTEC ITALY • Tel: 39 039 6890337 SAMTEC NORDIC/BALTIC • Tel: +46-84477280 SAMTEC BENELUX • Tel: 44 01236 739292
SAMTEC ISRAEL • Tel: 972-3-7526600 SAMTEC INDIA • Tel: +91-80-3272 1612 SAMTEC ASIA PACIFIC • Tel: 65 6745-5955 SAMTEC JAPAN • Tel: 045-475-1385 SAMTEC CHINA • Tel: 86-21-6083 3766
2735-6109 SAMTEC HONG KONG • Tel: 852-26904858 SAMTEC KOREA • Tel: 82-31-717-5685 SAMTEC ANZ • Tel: 613 9580 0683