



BWMR003027121R0T00

Search by :

Part Number

Characteristics

Cross reference



NEW



Closed Magnetic Circuit Type - Automatic Assembly

Series Pdf



RoHSREACHCoC




ICP Report



Product detail

L(mm) ±	3.0±0.20
W(mm) ±	2.7±0.20
T(mm) ±	1.2Max.
Inductance(uH)	1
Tolerance(±%)	30
Test Frequency	1MHz,200mV
SRF(MHz)Min	52
RDC(Ω)Max	0.064
Isat(A)Typ	5.4
Isat(A)Max	4.8
Irms(A)Typ	3
Irms(A)Max	2.7
Operating Temperature	− 40℃~ 125℃(Including self - temperature rise)

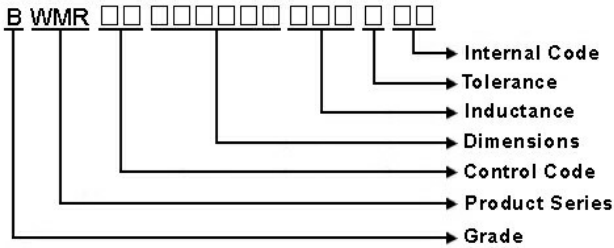

Products

- Power Inductor
- EMI-Common Mode Choke
- EMI-Bead
- RF-Signal Inductor
- RF-Passives/Antennas
- LAN Transformer
- Resistor & Current Sensor

Applications

- Automotive
- Industrial
- Server/DataCenter
- Communication
- Mobile and Tablet
- Computer/Laptop
- Consumer

Design Tools

- Simulation Tool
- Product Search Engine
- E-Catalogue

About Us

- Corporate Overview
- Corporate Milestones
- Core Technology
- Certificates & Awards
- Quality and Social Responsibility

Investor

[Financial Information](#)

[Corporate governance](#)

[Stakeholder Contacts](#)

News

[Media Center](#)

[New Products](#)

[Events](#)

[Product Notices](#)

Contact Us

[Contact Info](#)

[Contact Form](#)

[Join Chilisin](#)

[Terms of Use](#)

[Privacy policy](#)

[Sitemap](#)



Inductor



Resistor



Powder

Copyrights © 2018. Chilisin. All rights reserved.