


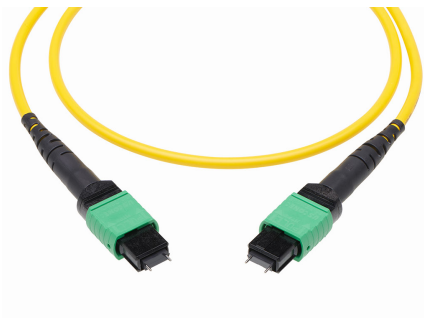

Part Number : [1062830205](#)
Product Description : QSFP-DD MPO-to-MPO Patch Cord, 9/125µm, 3.00mm, Singlemode, 16 Fiber, 5.0m Length, Yellow Cable
Series Number : 106283
Status : Active
Product Category : Fiber Optic Cable Assemblies



Documents & Resources

Drawings
[Drawing 1062830205_sd.pdf](#)

Specifications
[Application Specification 1062840501-000.pdf](#)
[Product Specification 1062830201-000.pdf](#)

Product Environment Compliance

Compliance

GADSL/IMDS	Not Reviewed
China RoHS	Not Reviewed
EU ELV	Not Reviewed
Low-Halogen Status	Not Reviewed
REACH SVHC	Not Reviewed
EU RoHS	Not Reviewed

Multiple Part Product Compliance Statements

- Eu RoHS
- REACH SVHC
- Low-Halogen

Multiple Part Industry Compliance Documents

- IPC 1752A Class C
- IPC 1752A Class D
- Molex Product Compliance Declaration
- IEC-62474
- chemSHERPA (xml)

Part Details

General

Status	Active
Category	Fiber Optic Cable Assemblies
Series	106283
Description	QSFP-DD MPO-to-MPO Patch Cord, 9/125µm, 3.00mm, Singlemode, 16 Fiber, 5.0m Length, Yellow Cable
Connector to Connector	MPO/APC-to-MPO/APC
Keyword	16F
Mode	Singlemode
Product Family	Optoelectronic Solutions
Product Name	MPO,QSFP-DD Optical Cables
UPC	195842046382

Agency

CSA	LR64395
UL	E72548

Physical

Boot Type	Straight
Cable Length	5.0m
Cable Size	3.00mm
Fiber (Core/Cladding)	9/125µm
Single Ended	No
Wire/Cable Type	16 Fiber SM Bend-insensitive Plenum