


PLEASE CHECK WWW.MOLEX.COM FOR LATEST PART INFORMATION

Part Number: 1201140034
Status: Active
Overview: Brad Micro-Change (M12) Connectors
Description: Micro-Change Molded Junction Box, Top Mount, 4 Ports, 2 (IO) per port, no LEDs, with Field Wireable Home Run Connection

Documents:	
Drawing (PDF)	RoHS Certificate of Compliance (PDF)

Agency Certification	
CSA	LR6837
UL	E152210
General	
Product Family	Passive Distribution Boxes
Series	120114
IP Rating	IP67
NEMA Rating	NEMA 6
Overview	Brad Micro-Change (M12) Connectors
Product Name	Micro-Change (M12)
UPC	78678887574
Physical	
Bus I/O	Micro-Change (M12)
Cable Connector Orientation	90° Angle
Cable Length	N/A
Home Run Cable Length	N/A
Home Run Connector	Terminal Strip
Home Run Interface	Terminal Strip
Keyway	Single
LED Indicator	No
Material - Cable Jacket	N/A
Material - Housing	PBT
Material - Metal	Copper Alloy
Material - Plating Mating	Gold over Nickel
Orientation	Top Mount
Poles	5
Poles (wired)	5
Ports	4
Temperature Range - Operating	-20°C to +90°C
Wiring Configuration	Dual I/O per Port
Electrical	
Current - Maximum per Contact	12.0A per module, 4.0A per port
Functional Wiring	Parallel
Voltage - Maximum	10-30V DC
Material Info	
Engineering Number	BTY4030-FBA
Reference - Drawing Numbers	
Sales Drawing	SD-120114-012

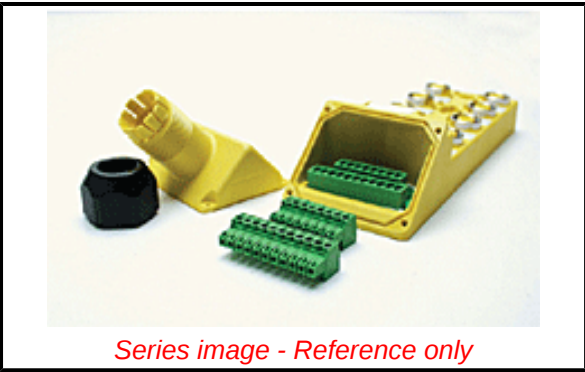

EU ELV	
Not Relevant	
EU RoHS	China RoHS
Not Compliant	
REACH SVHC	
Not Reviewed	
Halogen-Free Status	
Not Low-Halogen	
For more information, please visit Contact US	
China ROHS	Not Reviewed
ELV	Not Relevant
RoHS Phthalates	Not Reviewed

Search Parts in this Series
120114 Series

PLEASE CHECK WWW.MOLEX.COM FOR LATEST PART INFORMATION