

PLEASE CHECK WWW.MOLEX.COM FOR LATEST PART INFORMATION

Part Number: 0039010053
Status: Planned for Obsolescence
Description: 2.50mm (.098") Pitch Wire-to-Board Receptacle Housing, Low Profile, 5 Circuits

Documents:
[Drawing \(PDF\)](#) [RoHS Certificate of Compliance \(PDF\)](#)
[Product Specification PS-5480-001 \(PDF\)](#)

Agency Certification

CSA LR19980
UL E29179

General

Product Family Crimp Housings
Series 5480
Application Signal
Product Name N/A

Physical


Circuits (maximum) 5
Color - Resin Natural
Flammability 94V-0
Gender Female
Glow-Wire Compliant No
Material - Resin Polyester
Number of Rows 1
Packaging Type Bag
Panel Mount No
Pitch - Mating Interface 2.50mm (.098")
Stackable No
Temperature Range - Operating -40°C to +105°C

Material Info

Old Part Number 5480-05

Reference - Drawing Numbers

Product Specification PS-5480-001, RPS-5480-001, RPS-5480-002,
RPS-5480-003, RPS-5483-001, RPS-5483-002
Sales Drawing SD-5480-N

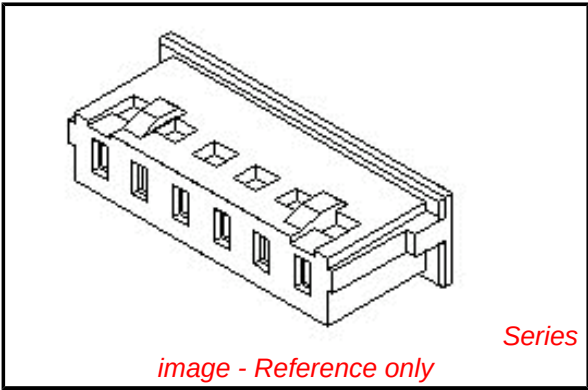

EU RoHS
ELV and RoHS
Compliant
REACH SVHC
Contains SVHC: No
Low-Halogen Status
Not Low-Halogen

China RoHS



Need more information on product environmental compliance?

Email productcompliance@molex.com
For a multiple part number RoHS Certificate of Compliance, [click here](#)

Please visit the [Contact Us](#) section for any non-product compliance questions.

Search Parts in this Series
5480Series

Mates With
5483 , 5484

Use With
5479

PLEASE CHECK WWW.MOLEX.COM FOR LATEST PART INFORMATION