

Heatsinks f.cool

Cases f.case

Connectors f.con

- Sockets
- PCB connectors
- IDC-connectors
- D-Sub connectors
 - D-Sub standard connectors
 - D-Sub connectors High Density
 - D-Sub filter connector
 - D-Sub connector for flat ribbon cable
 - D-Sub mixed layout connectors
 - D-Sub in SMD-mounting
 - D-Sub connector in pressfit technology
 - D-Sub hoods
 - D-Sub accessories
- Brackets for PC
- Optoelectronics

D-Sub filter connector


FD S ... LA ...

FD S 09 L 1000

Male headers, straight; capacity per contact: 1000 pF

Data sheet

add to request

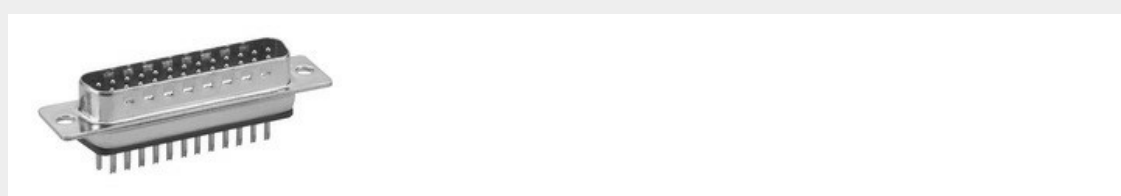

Features

Technical Drawing

Variants

Service

Accessories / related products

contact material

surface contact /

contact sleeve

quality class / cyces of operation

volume resistance

air gap and creep distance

nominal current

nominal voltage

test voltage

insulating body material

temperature range

casing frame

class of inflammability

insulation resistance

Cu-alloy

hard gold plated over nickel

quality class 2 = 200 cycles of operation

≤10 mΩ before strain, ΔR 10 mΩ after strain according to DIN 41652. part 2 (MIL-C-24308)

cont.-contact <1mm

contact-earth <1mm

5A (20°C)

100 V DC

250 V DC

PCT, GF

-55°C... +125°C

steel, tin plated

UL 94 V-0

≥1 GΩ (100V DC)