




Color: ■ black

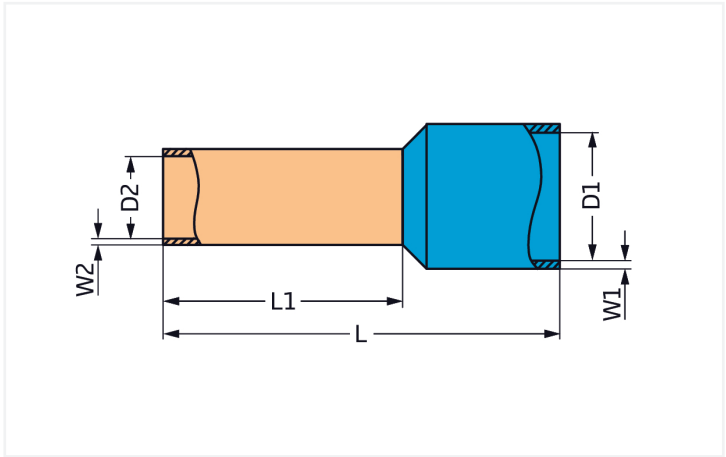

Dimensions in mm

Connection data	
Metric cross-section of the ferrule	1.5 mm²
Strip length	8 ... 9 mm / 0.31 ... 0.35 inches
Cross-section (AWG) of ferrule	16 AWG

Physical data	
Total length	12 mm
Wall thickness of crimp sleeve	0.15 mm
Wall thickness (plastic collar)	0.25 mm
Crimp length (length of sleeve)	6 mm
Inner diameter of plastic collar	3.5 mm
Diameter crimp sleeve inside	1.7 mm

Mechanical data	
Plastic collar	Standard collar

Material data	
Color	black
Fire load	0 MJ
Weight	0.1 g

Commercial data	
Product Group	2 (Terminal Block Accessories)
PU (SPU)	1000 pcs
Packaging type	Box
Country of origin	DE
GTIN	4017332277488
Customs tariff number	85369010000



Product Classification		
UNSPSC		39121405
eCl@ss 10.0		27-40-02-01
eCl@ss 9.0		27-40-02-01
ETIM 9.0		EC000005
ETIM 8.0		EC000005
ECCN		NO US CLASSIFICATION

Environmental Product Compliance	
RoHS Compliance Status	Compliant,No Exemption

Downloads

Environmental Product Compliance


Compliance Search

Environmental Product Compliance 216-224

↓

Documentation				
Bid Text				
216-224	11.09.2017	doc	23.50 KB	↓
216-224	19.02.2019	xml	2.80 KB	↓

Installation Notes

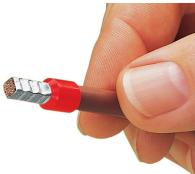

A perfect gas-tight crimp – both electrical-ly and mechanically reliable