

Quick Links

Cross reference

RoHS/LF P/N Search

Industry Standards

Alphabetical List

Documentation

3D model search

Customer drawing search


Multi Selection Search

Search by category

Start > Search=H516505200J0G* > H516505200J0G

H516505200J0G

H516505200J0G - Terminal Blocks : pluggable plug with spring connection, 5.08mm pitch, male connector, flange with nut, 16 position

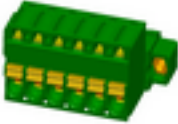

ACTIVE

Distributor Stock

Print Datasheet

FCI Brings You More

Contact our sales/technical support

Sample request

Customer drawing

Environmental Compliance Report

Specifications

Download document

Mating Half

General	Dimensional	Electrical	Physical	Approvals / Certifications
General				
Gender	Male plug			
Packaging	Box			
Product Type	Spring Clamp Pluggable System			
Series	H5			
Number of Positions	16			
Dimensional				
Strip length (Wire)	9 to 10 mm			
Solid wire size (AWG)	12 to 26			
Stranded wire size (AWG)	12 to 26			
Pitch	5.08 mm			
Electrical				
Withstanding Voltage	1.6 kV			
Current rating	10 A			
Voltage rating	300 V			
Physical				
Color (Housing)	Green			
Conductor entry angle	0°			
Material (Housing)	Thermoplastic UL94V-0			
Terminal material	Phosphor bronze			
Terminal plating	Tin			
Connection Type	Spring connection			
Temperature (Operating - range)	-40 to 115 Celcius			
Approvals / Certifications				
Approvals / Certifications	cULus			

Disclaimer : The information above is for reference only. For more technical details, refer to product specification and application specification.