


BU-60 Series (Uninsulated Steel Alligator Clips)



BU-60 / BU-60HT / BU-60S / BU-60X



BU-60BLACK

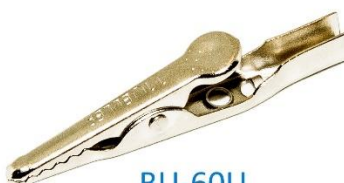

BU-60U



BU-60PR2



BU-60G



BU-60TBO



BU-60S

- Mueller Electric's BU-60 is the most common and versatile alligator clip. Compatible with BU-62 and BU-62S high-temperature PVC insulators.
- Overall length 1.96" (50.1mm), overall width 0.31" (7.9mm), maximum jaw spread = 0.31" (7.9mm)
- Can be attached to wire via solder or crimp connection.
- Ratings: Current 10 Amps
- The BU-60 is sold under the following models:

BU-60	Nickel-plated steel clip, compatible with 4mm banana plugs
BU-60HT	Zinc-plated steel BU-60, rated to 1100°F (593°C)
BU-60X	Stainless-steel BU-60 (including hardware)
BU-60BLACK	Black BU-60
BU-60G	Gold-plated steel BU-60
BU-60U	BU-60 with U-shaped barrel
BU-60TBO	BU-60 with 8-32 threaded barrel
BU-60PR2	BU-60 with phone tip/test prod tip connection
BU-60S	BU-60 with #6 screw for wire attachment
- RoHS 3 compliant

Mueller Electric Company
2850 Gilchrist Rd. Bld 5A
Akron, OH 44305

www.muellerelectric.com

Toll Free: 800.955.2629
Phone: 330.780.2525
Fax: 330.780.2524