


MPZ1608D101BTA00



Applications	 Commercial Grade
Feature	 Power line
Series	MPZ
Status	 Production
Brand	TDK

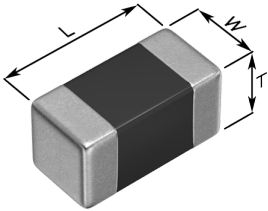



Size	
Length(L)	1.60mm ±0.15mm
Width(W)	0.80mm ±0.15mm
Thickness(T)	0.80mm ±0.15mm
Recommended Land Pattern (A)	0.60mm Nom.
Recommended Land Pattern (B)	0.80mm Nom.
Recommended Land Pattern (C)	0.80mm Nom.

Electrical Characteristics	
Impedance at 100MHz	100Ω ±25%
Rated Current	1A
DC Resistance (Max.)	150mΩ

Other	
Operating Temp. Range (Including Self-Temp. Rise)	-55 to 125°C
Soldering Method	Reflow Iron Soldering
AEC-Q200	NO
Packing	Punched (Paper)Taping [180mm Reel, Tape width 8mm]
Package Quantity	4000pcs
Weight	0.004g



Characteristic Graphs(This is reference data, and does not guarantee the products characteristics.)

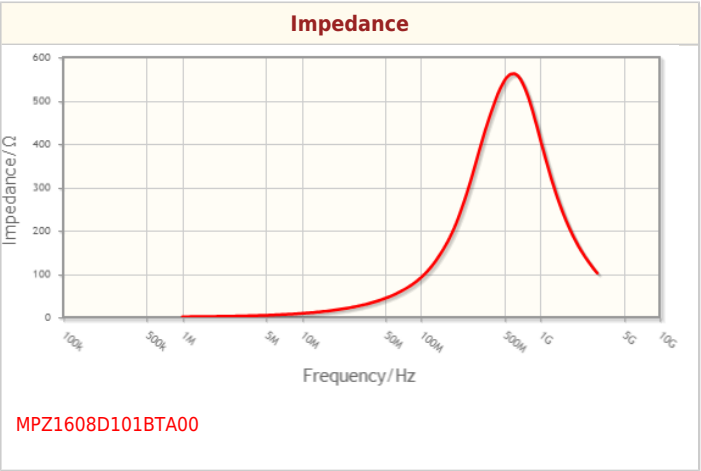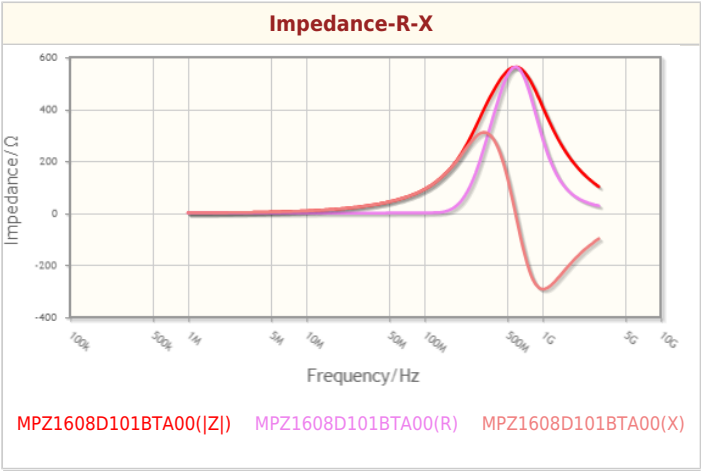



Associated Images

