


PXMBNI78FPM03APC78 Datasheet



Product Name // 3 Contacts 7/8" Front Panel Mounting Male Connector

[View Product Page](#)

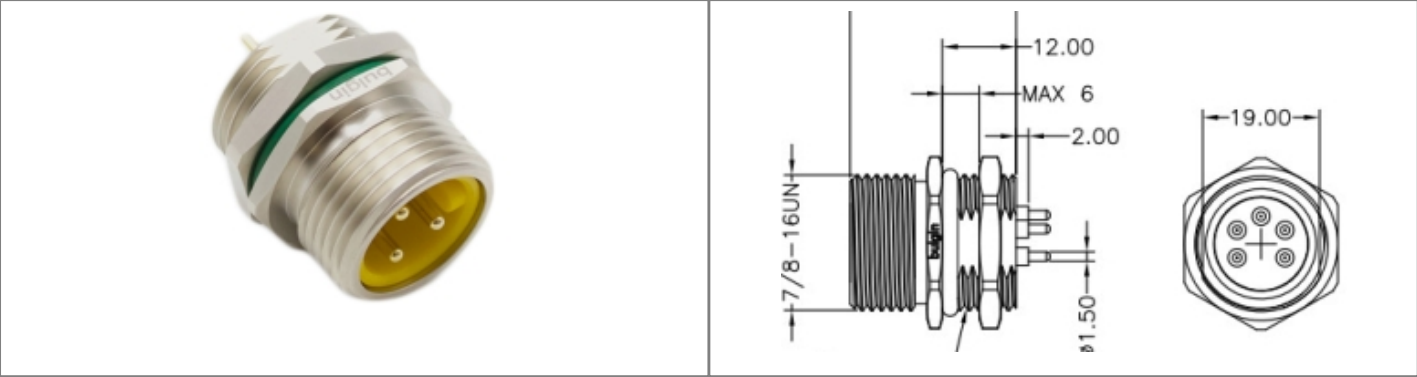

// Product Description:

- 3 Contacts 7-8" Front Panel Mounting Male Connector
 - IP67 rated when mated
 - Mechanical Cycles >100
- Operating Temperature -25°C to +85°C
 - Rated Voltage 300 V
 - ROHS compliance

// General Information:

Product Display Title:	7/8" Front Panel Mounting Male Connector
Product Family:	Circular Automation Connectors
Product Series:	7/8" Series
Connection Method:	PCB
Contact Pin Material:	Brass gold plated 1u"
Contact Type:	Plug Contact
Current Max:	12A
Durability:	>100 Cycles
Function:	Front Panel Mounting Male Connector
Insulation Resistance:	>100MOhm
Ip Rating:	IP67
Max Operating Temperature:	+85°C
Min Operating Temperature:	-25°C
Max Panel Thickness:	6.0mm
Number Of Contacts:	3 Contacts
Panel Cut Out:	22.20mmx19.20mm
Pcb Thickness:	>2.5mm
Pin Layout Code:	A Code
Rohs Compliant:	Yes
Thread Size:	7/8-16UN
Voltage Max:	300V

// Product PDF Links



// Product 3D CAD Model Links



Have a question or project enquiry
you'd like to talk to us about?



[Click Here To Contact Us](#)