


COIL: @ 25°C  
 RESISTANCE 50 OHMS ± 10%  
 NOMINAL VOLTAGE 5.0 VDC  
 MUST OPERATE 3.6 VDC  
 MUST RELEASE \_\_\_\_\_

ENVIRONMENT:

VIBRATION 10 CPS TO 500 CPS @ 10 g's  
 SHOCK 30 g's 6 MS. DURATION  
 TEMPERATURE -55 °C TO +85 °C

NOTES: OPERATE TIME 4.0 MS MAX.  
RELEASE TIME 6.0 MS MAX.

CUSTOMER DATA SHEET

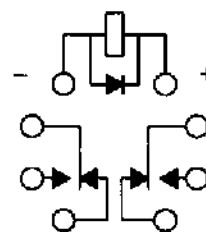

CONTACT RATING: LOW LEVEL TO 1A  
28 VDC RESISTIVE 100,000 OPERATIONS

DR. R.B. 4/28/98 *ER* 4/21/98

**COMMUNICATIONS**  
**INSTRUMENTS, INC.**

**HMD-5B**

CUST. C. I. I. STD.  
 CUST. NO. \_\_\_\_\_

TYPE **HMD RELAY**