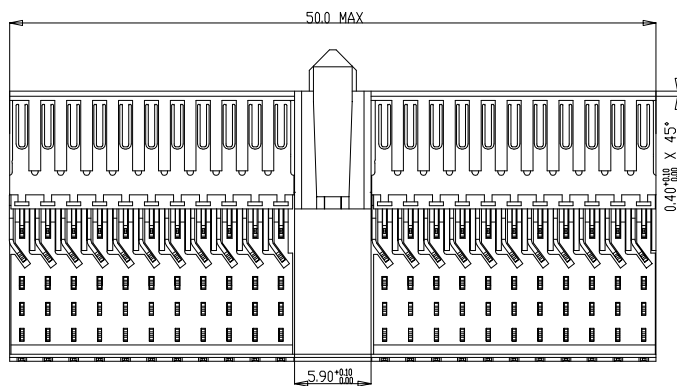
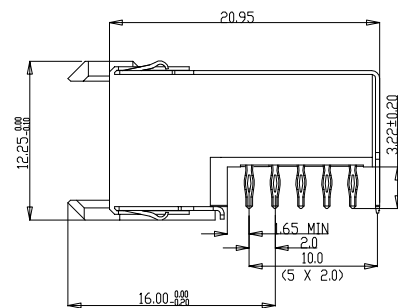
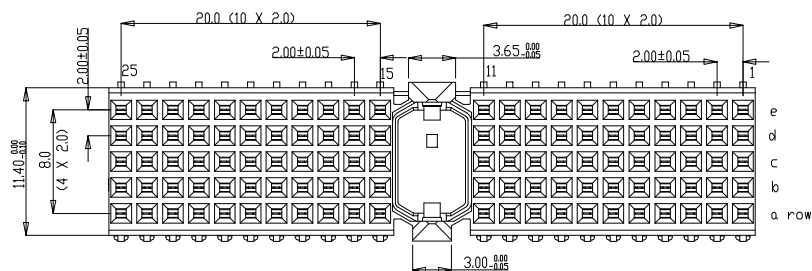


PERFORMANCE CHARACTERISTICS

15 A AT 20°C (FULLY LOADED)
CURRENT RATING 1 A AT 70°C (FULLY LOADED)

RATED VOLTAGE 500V AC (CONT / CONT)
OPERATING TEMPERATURE -55°C TO 125°C
CONTACT RESISTANCE 20 MΩ MAX
INSERTION FORCE :0.75 N MAX /CONT
EXTRACTION FORCE: 0.15 N MIN /CONT
INSULATION RESISTANCE :10⁴ MΩ MIN

NOTES

1. LEAD FREE INDICATOR : LF- LEAD FREE
2. THIS PRODUCT IS CSA APPROVED
THIS PRODUCT IS UL RECOGNISED
3. FOR RECOMMENDED PTH DIMENSIONS REFER DRAWING: BSA,201,572001
4. THIS PRODUCT (LF) MEETS EUROPEAN UNION DIRECTIVE
AND OTHER COUNTRY REGULATIONS AS DESCRIBED IN GS-22-008.

Material				Spec ref			
Mat code				tolerance			
Heat treat				projection			
Plating/Finish				MM			
rev	ecn no	dr	date	Dr	4	2	92
A	CONV	KN	14-9-91	Eng	W.Panis	Product family	MILLIPACS
B	105-0093	MINI	08/06/05	Chr		Model Name	HM2R10P5A101----
C	3005-0278	KASIN	02/08/05	Appr		Model Revision	ECN
D	3007-0362	Kason	05/09/07			REL Level	
E	5010-0010	NZ	05/10/10				
-	-	-	-				
FCI				MPACS 5+2R RA RCP			
Pro/E file				CONN TYPE A			
catalog no				HM2R10P5A101----			
				CUSTOMER DRAWING			