

» MPC-pONE «



Aluminum housing / 1:1 scale


MICROSPACE®

The small and fanless MICROSPACE®-pONE box with Intel® Atom™ Z510 or Z530 processor

- » Bootable microSD support
- » High performance combined with lowest power consumption for low/optimized costs
- » DIN rail mounting kit available
- » Possible application: information terminals

Technical Information

Processor / Performance	Intel® Atom™ Z510 / 1.1GHz or Z530 / 1.6GHz
Mass Storage	2.5" SATA SSD / HDD, mSD
Memory	1x DDR2 SODIMM, up to 2GB
Graphics	DVI (UXGA)
Ethernet	1x 1 Gbit LAN
USB	4x USB 2.0 (2x front, 2x rear)
Audio	2x stereo line-in, line-out
Operating temperature	0°C to +45°C
Size (W x L x H in mm)	122 x 53 x 99/105
Weight	0.6 kg
Housing	Aluminium
Special features	Optional: 2GB DDR2 RAM, SSD 40GB, HDD 500GB (planned), DIN rail kit, power supply

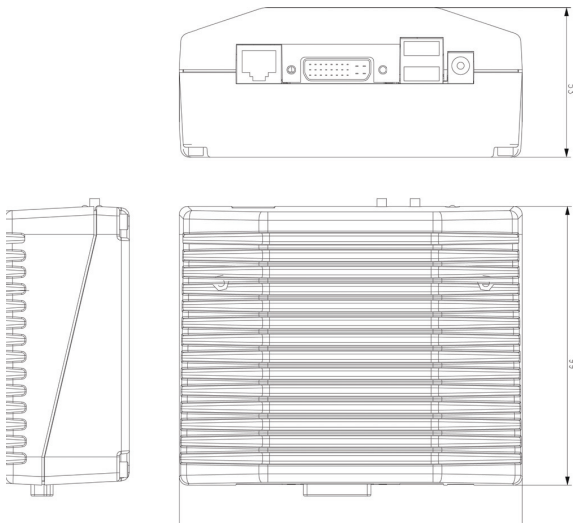

Ordering Information

Article	Part No.	Description
MPC-pONE 1.1GHz	812200	Intel® Atom™ Z510 / 1.1GHz, 1GB RAM
MPC-pONE 1.6GHz	812201	Intel® Atom™ Z530 / 1.6GHz, 1GB RAM
RAM 2GB DDR2 SODIMM	807364	Upgrade to 2GB DDR2 RAM
Hard Disk 320GB	890046	Hard disk 320GB
Solid State Drive 2.5" 40GB	807417	SSD 40GB
Solid State Drive 2.5" 80GB	890116	SSD 80GB
Micro SD Flash 4GB	872150	Internal Micro SD card, 4GB Tiny core Linux
Power supply adapter	812210	Power supply; 230V AC to +5V DC
DIN Rail Kit	812031	Kit for DIN Rail (EN50022) mounting

CORPORATE OFFICES

Europe, Middle East & Africa

Oskar-von-Miller-Str. 1
85386 Eching / Munich
Germany

Tel.: +49 (0) 8165 / 77 777
Fax: +49 (0) 8165 / 77 219
info@kontron.com

North America

14118 Stowe Drive
Poway, CA 92064-7147
USA

Tel.: +1 888 294 4558
Fax: +1 858 677 0898
info@us.kontron.com

Asia Pacific

17 Building, Block #1, ABP.
188 Southern West 4th Ring Road
Beijing 100070, P.R.China

Tel.: +86 10 63751188
Fax: +86 10 83682438
info@kontron.cn