



Search by part # or keyword

[Products](#)

[Industries & Solutions](#)

[Resources](#)

TE Store

[Sign In](#)



[Connectors](#) > [D-Shaped Connectors](#) > [D-Sub Connectors](#) > [Box Mount D-Sub Connectors](#)

Purchase items directly from TE.com

211539-2

AMPLIMITE,ASY,RCPT,FB,90,4,CONT



AMPLIMITE

TE Internal #: **211539-2**
 TE Internal Description:
AMPLIMITE,ASY,RCPT,FB,90,4,CONT
 Mil-Spec: **M24308/2-350F**

Connector Style : **Receptacle**
 Connector System : **Cable-to-Cable**
 Number of Positions : **62**
 Power/Signal/Coax Combination : **No**
 Shell Size : **4**

[Similar Products](#) | [Digital Datasheet](#)

Compatible Parts & Tooling

We are here to help!

Get in touch with our product experts.



CHAT WITH US



EMAIL US



CALL US

Documents

Features

Product Compliance

Product Drawings

AMPLIMITE,ASY,RCPT,FB,90,4,CONT
[↓ AMPLIMITE,ASY,RCPT,FB,90,4,CONT](#) English

CAD Files

3D PDF
[↓ 3D_CVM_CVM_211539-2_K.pdf](#) 3D
 Customer View Model
[↓ ENG_CVM_CVM_211539-2_K.2d_dxf.zip](#)
 English
[↓ ENG_CVM_CVM_211539-2_K.3d_igs.zip](#) English
[↓ ENG_CVM_CVM_211539-2_K.3d_stp.zip](#)
 English

Datasheets & Catalog Pages

Sealed AMPLIMITE D-Subminiature Connectors
[↓ ENG_DS_1-1773853-7_dsub67_0516.pdf](#)
 English

Product Environmental Compliance

REACH Substance Communication Document
[↓ ENG_PC_RSCD_Cadmium_3.pdf](#) English

Agency Approvals

UL Report
[↓ ENG_AAD_UL_E28476_19881201_B.pdf](#) English



Please review product documents or [contact us](#) for the latest agency approval information. Please Note: Use the Product Drawing for all design activity.

Product Type Features	Connector Style : Receptacle Connector System : Cable-to-Cable Shell Size : 4 Sealable : No Connector & Contact Terminates To : Wire & Cable Blindmate : No
Configuration Features	Number of Positions : 62 Power/Signal/Coax Combination : No
Body Features	Non-Magnetic : No
Contact Features	Contact Base Material : Beryllium Copper Contact Size : 22 Contact Current Rating (Max) (A): 5
Housing Features	Centerline (Pitch) : 2.29 mm [.09 in]
Usage Conditions	Operating Temperature Range : -50 – 125 °C [-22 – 257 °F]
Operation/Application	Circuit Application : Signal
Statement of Compliance	Statement of Compliance pdf

Products with Similar Specs

[View All Similar Products](#)

THIS PRODUCT

TOP RESULTS

BOX MOUNT D-SUB CONNECTORS

211539-2

AMPLIMITE, ASY, RCPT, FB, 90, 4, CONT



Non-Stocked

Connector Style : **Receptacle**
Connector System : **Cable-to-Cable**

Number of Positions : **62**

Power/Signal/Coax Combination :

BOX MOUNT D-SUB CONNECTORS

211541-2

AMPLIMITE, ASY, RCPT, FB, 90, 6, CONT



In-Stock

Connector Style : **Receptacle**
Connector System : **Cable-to-Cable**

Number of Positions : **104**

Power/Signal/Coax Combination :

BOX MOUNT D-SUB CONNECTORS

211538-1

AMPLIMITE, ASY, RCPT, FB, 90, 3



In-Stock

Connector Style : **Receptacle**
Connector System : **Cable-to-Cable**


Number of Positions : **44**

Power/Signal/Coax Combination : **No**

BOX MOUNT D-SUB CONNECTORS

204530-1

AMPLIMITE, ASY, RCPT, FB, 90, 4

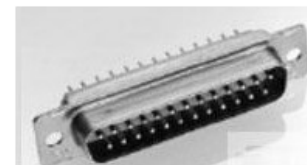

In-Stock

Connector Style : **Receptacle**
Connector System : **Cable-to-Cable**

Number of Positions : **62**

Power/Signal/Coax Combination : **No**

[ABOUT TE CONNECTIVITY](#)

[FOR PARTNERS](#)

[SUPPORT](#)

[CALL US](#)

[LIVE CHAT](#)

[UNITED STATES \(EN\)](#)