


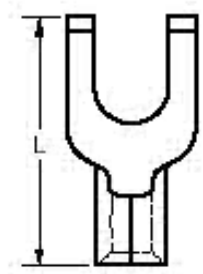

Part Number : [191180086](#)
Product Description : Krimptite Flanged Spade
Tongue Terminal for 12-10 AWG Wire, Stud Size 8 (M4),
Length 19.56mm, Carton
Series Number : 19118
Status : Active
Product Category : Ring and Spade Terminals
Engineering Part Number : C-117-08



Documents and Resources

Drawings

[191180086 sd.pdf](#)
[PK-19902-001-001.pdf](#)

3D Models and Design Files

[STEP AP242](#)
[SOLIDWORKS](#)
[Creo](#)

Specifications

[PS-19902-013-001.pdf](#)

Product Environment Compliance

Compliance

GADSL/IMDS	Not Relevant
China RoHS	 per SJ/T 11365-2006
EU ELV	Not Relevant
Low-Halogen Status	Low-Halogen per IEC 61249-2-21
REACH SVHC	Not Contained per D(2025)7771-DC (04 Feb 2026)
EU RoHS	Compliant per EU 2015/863

[Compliance Statements](#)

- EU RoHS

- REACH SVHC
- Low-Halogen

Industry Documents

- IPC 1752A Class C
- IPC 1752A Class D
- Molex Product Compliance Declaration
- IEC-62474
- chemSHERPA (xml)

Substances of Interest

- PFAS

EU RoHS Certificate of Compliance

Additional Product Compliance Information

Part Details

General

Status	Active
Category	Ring and Spade Terminals
Series	19118
Description	Krimptite Flanged Spade Tongue Terminal for 12-10 AWG Wire, Stud Size 8 (M4), Length 19.56mm, Carton
Keyword	Spade Terminal, Spade Terminals
Product Name	Krimptite
Style	Spade
Type	Spade Connector, Metric Spade Connector
UPC	800755082814

Agency

CSA	LR18689
UL	E32244

Physical

Barrel Type	Closed
Insulation	None
Material - Plating Mating	Tin

Net Weight	1.511/g
Packaging Type	Carton
Plating min - Mating	4.064µm
Plating min - Termination	4.064µm
Stud Size	8 (M4)
Wire Size (AWG)	10, 12
Wire Size mm ²	4.00-6.00

Application Tooling

Global

Description	Part Number
PremiumGrade Hand Crimp Tool for Krimptite/Versakrimp Terminals and Splices, 22-10 AWG and 6.0mm ² - 0.5mm ²	<u>640030100</u>
ServiceGrade Hand Crimp Tool - Ratchet	<u>640160038</u>

This document was generated on Apr 29, 2026