

[Products](#)[Customize Your Parts](#)[Industries Solutions](#)[Search](#)[News & Events](#)[First Time?](#)

(0)



Home / Products / FLOS & FLOS+ / Y Series B Size

Product Line

Single Pair Ethernet

>

ZConnect

>

Ceres

>

X-Lok

>

M Series

>

FLOS & FLOS+

>

Accessory

B Series A Size

B Series B Size

B Series C Size

B Series D Size

K Series B Size

K Series C Size

K Series D Size

Y Series B Size

Power

>

RBL

>

HS-Lok

>

NM51-0000

Heavy Duty Shielded

>

RJ

>

USB

>

SSL

>

HDMI

>

DVI

>

Fiber Optic

>

RF

>

Cable Joiner

>

Cable Gland

>

Pressure Relief Vent


>

LED Light Guide

>

D-Sub

>

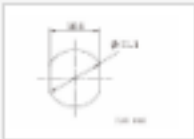

FDYB-09EEFP-RDK-001

Operating Temperature: -40°C ~ +125°C

Transmission Speed: N/A

Shielded: Metal, Shielded

Jacket Material: N/A

Certificate: N/A

You must login first for view the price

Quantity

- 1 +

Check Stock

Add to Cart

Inquiry



Can't find? [Customize your part](#)

Mating Pair & Accessories

Connector Type

Search



FLOS, Y Series B Size,...
FDYB-09A1MS-RDK

- 0 +



Add to Cart

Inquiry

ABOUT AMPHENOL LTW

SUPPORT

PARTNERS

DOWNLOAD CENTER

FEEDBACK

Specifications

Download / CAD

Nominal Current

5A

Connector Type

Receptacle

Shielded

Metal, Shielded

No. of Contacts

09

Connector Gender

Female

Backshell

Circular

Mating Style

Push Pull

IP Rating

IPX8

Assembly Style

PCB 180°

More Options

People Also Bought

