

Part Number : [1211290289](#)


Product Description : mPm DIN Silicone, Gasket
Non-loosing, Form A-18mm with Retention Feature, 1
Bag of 50

Series Number : 121129

Status : Active

Product Category : Circular Industrial Connectors

Engineering Part Number : 3012-17

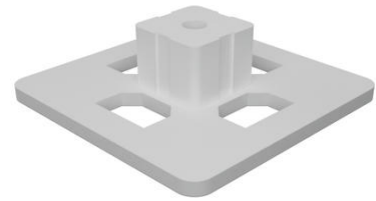

Documents and Resources

Drawings

[1211290289 sd.pdf](#)


[STEP AP242](#)

[SOLIDWORKS](#)

[Creo](#)

Product Environment Compliance

Compliance

GADSL/IMDS	Not Relevant
China RoHS	 per SJ/T 11365-2006
EU ELV	Not Relevant
Low-Halogen Status	Low-Halogen per IEC 61249-2-21
REACH SVHC	Contains Dodecamethylcyclohexasiloxane; Decamethylcyclopentasiloxane; Octamethylcyclotetrasiloxane per D(2025)4165-DC (25 June 2025)
EU RoHS	Compliant per EU 2015/863

Compliance Statements

- EU RoHS
- REACH SVHC
- Low-Halogen

Industry Documents

- IPC 1752A Class C
- IPC 1752A Class D
- Molex Product Compliance Declaration
- IEC-62474
- chemSHERPA (xml)

Substances of Interest

- PFAS

EU RoHS Certificate of Compliance

Additional Product Compliance Information

Part Details

General

Status	Active
Category	Circular Industrial Connectors
Series	121129
Description	mPm DIN Silicone, Gasket Non-loosing, Form A-18mm with Retention Feature, 1 Bag of 50
IP Rating	IP65, IP67
Product Name	mPm
Type	Field Attachable Connector
UPC	883906704087

Electrical

Current - Maximum per Contact	N/A
Voltage - Maximum	N/A

Physical

Cable Diameter	N/A
Coupling Type	N/A
Diagnostics / LEDs	No
Diagnostics Port	No
Form	A - 18mm
Gender	N/A
Keyway	None

Material - Connector Body	Silicone
Material - Contact	N/A
Material - Coupling Nut	N/A
Material - Plating Mating	n/a
Net Weight	97.500/g
Orientation	N/A
Pitch - Mating Interface	N/A
Poles	N/A
Temperature Range - Operating	N/A
Wire Size (AWG)	N/A

This document was generated on May 06, 2026