

PLEASE CHECK WWW.MOLEX.COM FOR LATEST PART INFORMATION

Part Number:

130115-0227

Status:

Active


Description:

Pow-R-Feed® Sliding Hanger Bracket, Epoxy Coat, Length 32.00mm (1.260")

Documents:

RoHS Certificate of Compliance (PDF)

General	
Product Family	Conductor Bars
Series	130124
Component Type	Bracket - Hanger
Current - Max. per Conductor	N/A
Depth	58.93mm (2.320")
Duty	Standard
Height	156.46mm (6.160")
Length	32.00mm (1.260")
Product Name	Pow-R-Feed
UPC	78678866149
Woodhead	Yes
Physical	
Material - Housing	Epoxy
Material - Metal	Galvanized Steel
Material - Resin	N/A
Material - Wheel	N/A
Net Weight	181.430/g
Packaging Type	Individual Carton
Temperature Range - Operating	-30°C to +60°C
Electrical	
Voltage - Maximum	600V
Material Info	
Old Part Number	ABN7L

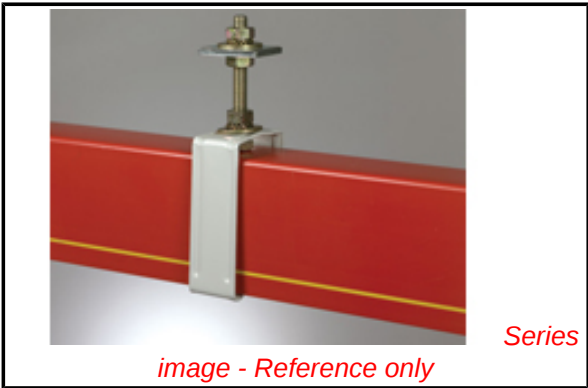

EU RoHS

China RoHS

RoHS Compliance

Not Required

REACH SVHC

Not Reviewed

Low-Halogen Status

Not Reviewed

Need more information on product environmental compliance?

Email productcompliance@molex.com
For a multiple part number RoHS Certificate of Compliance, [click here](#)

Please visit the [Contact Us](#) section for any non-product compliance questions.

Search Parts in this Series

130124Series

PLEASE CHECK WWW.MOLEX.COM FOR LATEST PART INFORMATION