

TOP-KNOBS

Uniquely modern tuning knobs

Our TOP-KNOBS are unique in design and are thus the ideal solution for users looking for that special something. Individual marking element define the function of the tuning knob and give your equipment a modern, contemporary appearance.

- aesthetically pleasing knob design *** iF product design award ***
- lateral fixing screw for axis corresponding to DIN 41591 or for flattened ends
- individual, functional marking elements, e.g. for fine calibration, clip into the sides and hide the lateral fixing screw
- the fixing technique rules out any possibility of contact with live parts
- recessed underside to allow for external potentiometer fixing nuts
- modern color combinations

knob sizes

ø 16 mm

4 mm, 6 mm, 6/4.6 mm

ø 20, 24, 31, 40 mm


4 mm, 6 mm, 1/4", 6/4.6 mm

boreholes

Designer Statement

"What looks like a play on shapes and colors in TOP-KNOBS is the result of an extraordinary design idea: The colored pins in the design variations Wing, Arrow, Disk, Globe and Pin cover the side screw in the knob body, with which the knobs are secured on the shaft. In addition to the attractive appearance, hygiene and labelling, a higher electrical safety level is also achieved. The many applications in which the award-winning knobs are used show that these design options are in demand. When do you want to fly the flag?"

Martin Nußberger, polyform Industrie Design

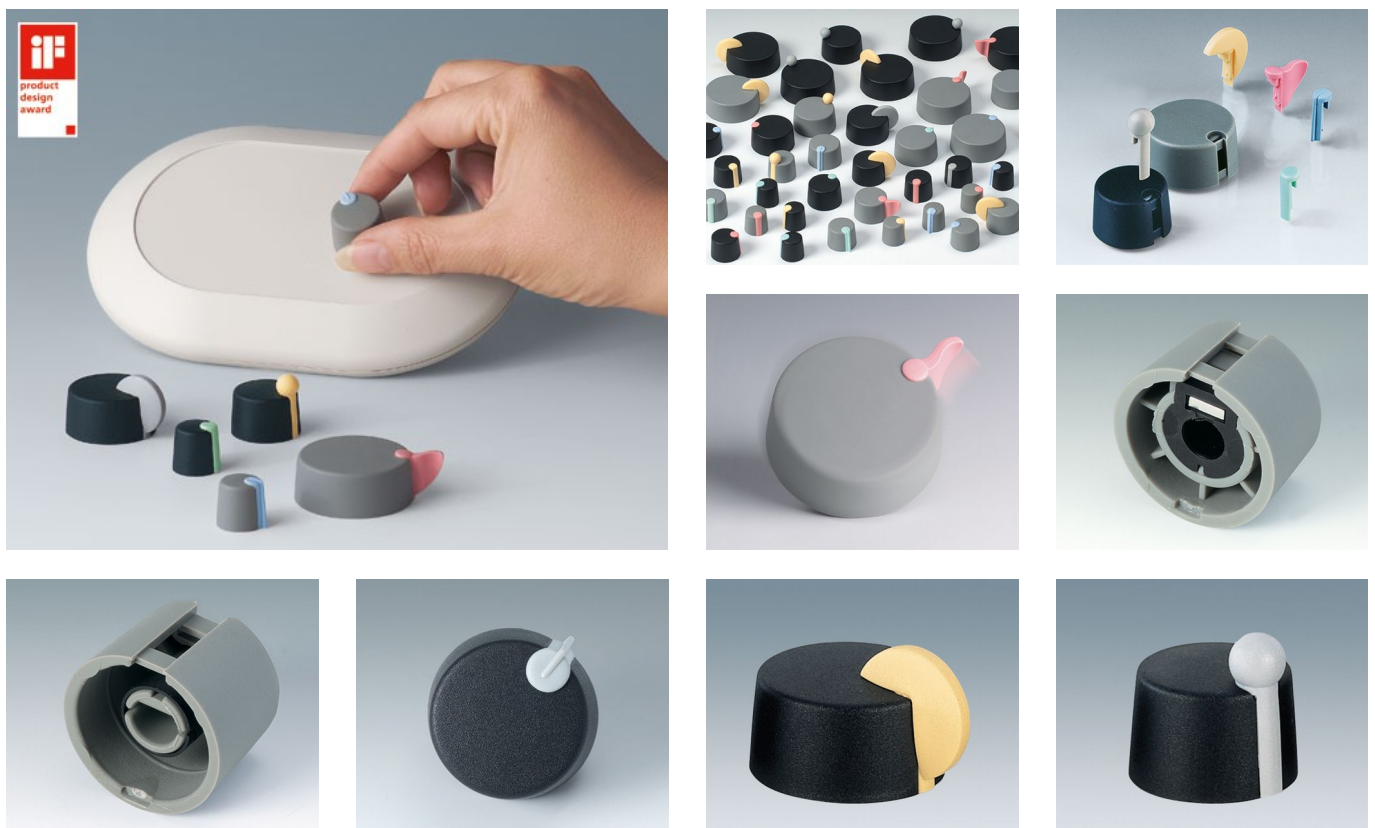

TOP-KNOBS

Applications and Examples

For rotary potentiometers with shaft ends corresponding to DIN 41591 or with flattened ends $\varnothing 6/4.6$ mm.

- Measuring and control technology
- Medical and wellness devices
- Laboratory equipment
- Heating and air conditioning
- Communication equipment
- Building management



Control knobs for video magnifier



Integrated thermostat for electric storage heaters



Operating element for a diagnostic device



Operating element for a vacuum cleaner

View Customizing Options

What do you still need for your own very personal product? We can supply enclosures and tuning knobs with all necessary modifications for fitting your electronic components.

Customizing options for Top-Knobs



Machining



Printing



Laser marking



Installation / Assembly
of accessories

Select Versions



A1016048
TOP-KNOBS 16
PA 6
volcano
16x16mm 4mm



A1016049
TOP-KNOBS 16
PA 6
nero
16x16mm 4mm



A1016068
TOP-KNOBS 16
PA 6
volcano
16x16mm 6mm



A1016069
TOP-KNOBS 16
PA 6
nero
16x16mm 6mm

TOP-KNOBS



A1016648
TOP-KNOBS 16
PA 6
volcano
16x16mm



A1016649
TOP-KNOBS 16
PA 6
nero
16x16mm



A1020048
TOP-KNOBS 20
PA 6
volcano
20x16mm 4mm



A1020049
TOP-KNOBS 20
PA 6
nero
20x16mm 4mm



A1020068
TOP-KNOBS 20
PA 6
volcano
20x16mm 6mm



A1020069
TOP-KNOBS 20
PA 6
nero
20x16mm 6mm



A1020638
TOP-KNOBS 20
PA 6
volcano
20x16mm 1/4"



A1020639
TOP-KNOBS 20
PA 6
nero
20x16mm 1/4"



A1020648
TOP-KNOBS 20
PA 6
volcano
20x16mm



A1020649
TOP-KNOBS 20
PA 6
nero
20x16mm



A1024048
TOP-KNOBS 24
PA 6
volcano
24x16mm 4mm



A1024049
TOP-KNOBS 24
PA 6
nero
24x16mm 4mm



A1024068
TOP-KNOBS 24
PA 6
volcano
24x16mm 6mm



A1024069
TOP-KNOBS 24
PA 6
nero
24x16mm 6mm



A1024638
TOP-KNOBS 24
PA 6
volcano
24x16mm 1/4"



A1024639
TOP-KNOBS 24
PA 6
nero
24x16mm 1/4"

TOP-KNOBS



A1024648
TOP-KNOBS 24
PA 6
volcano
24x16mm



A1024649
TOP-KNOBS 24
PA 6
nero
24x16mm



A1031048
TOP-KNOBS 31
PA 6
volcano
31x16mm 4mm



A1031049
TOP-KNOBS 31
PA 6
nero
31x16mm 4mm



A1031068
TOP-KNOBS 31
PA 6
volcano
31x16mm 6mm



A1031069
TOP-KNOBS 31
PA 6
nero
31x16mm 6mm



A1031638
TOP-KNOBS 31
PA 6
volcano
31x16mm 1/4"



A1031639
TOP-KNOBS 31
PA 6
nero
31x16mm 1/4"



A1031648
TOP-KNOBS 31
PA 6
volcano
31x16mm



A1031649
TOP-KNOBS 31
PA 6
nero
31x16mm



A1040048
TOP-KNOBS 40
PA 6
volcano
40x16mm 4mm



A1040049
TOP-KNOBS 40
PA 6
nero
40x16mm 4mm



A1040068
TOP-KNOBS 40
PA 6
volcano
40x16mm 6mm



A1040069
TOP-KNOBS 40
PA 6
nero
40x16mm 6mm



A1040638
TOP-KNOBS 40
PA 6
volcano
40x16mm 1/4"



A1040639
TOP-KNOBS 40
PA 6
nero
40x16mm 1/4"

TOP-KNOBS



A1040648
TOP-KNOBS 40
PA 6
volcano
40x16mm



A1040649
TOP-KNOBS 40
PA 6
nero
40x16mm

System components to complete



A1101003
Pin
PA 6 (UL 94 HB)
coral



A1101004
Pin
PA 6 (UL 94 HB)
beach



A1101005
Pin
PA 6 (UL 94 HB)
lagoon



A1101006
Pin
PA 6 (UL 94 HB)
sky



A1101007
Pin
PA 6 (UL 94 HB)
mineral



A1102004
Globe
PA 6 (UL 94 HB)
beach



A1102007
Globe
PA 6 (UL 94 HB)
mineral



A1103004
Disk
PA 6 (UL 94 HB)
beach



A1103007
Disk
PA 6 (UL 94 HB)
mineral



A1104003
Wing
PA 6 (UL 94 HB)
coral



A1105003
Arrow
PA 6 (UL 94 HB)
coral



A1105004
Arrow
PA 6 (UL 94 HB)
beach

TOP-KNOBS



A1105005
Arrow
PA 6 (UL 94 HB)
lagoon



A1105006
Arrow
PA 6 (UL 94 HB)
sky



A1105007
Arrow
PA 6 (UL 94 HB)
mineral

Accessory "screws"



A6207009
Round nut M7 x 0.75



A6210009
Round nut M10 x 0.75



A6295009
Round nut 3/8"-32G

Subject to technical modification without notice. © by OKW Gehäusesysteme, Buchen/Germany.