

PTF 0,3/ 4-FLEX-T-8 - PCB

 
1848493

<https://www.phoenixcontact.com/us/products/1848493>



Please be informed that the data shown in this PDF document is generated from our online catalog. Please find the complete data in the user documentation. Our general terms of use for downloads are valid.

PCB direct plug, color: white, number of positions: 4, product range: PTF 0,3/...-Flex, pitch: 1.8 mm, type of packaging: packed in cardboard



Your advantages

- T-distributor for implementing complex arrangements of flexible LED printed-circuit boards
- Easy connection of flexible LED printed-circuit boards
- Minimal heating during operation
- UL-approved materials

Commercial data

Item number	1848493
Packing unit	20 pc
Minimum order quantity	20 pc
Sales key	AA08
Product key	AAHRCA
GTIN	4055626282220
Weight per piece (including packing)	0.361 g
Weight per piece (excluding packing)	0.25 g
Customs tariff number	85340019
Country of origin	CN

PTF 0,3/ 4-FLEX-T-8 - PCB

1848493

<https://www.phoenixcontact.com/us/products/1848493>



Technical data

Product properties

Product type	PCB direct plug
Product family	PTF 0,3/..-Flex
Number of positions	4
Pitch	1.8 mm

Mounting

Mounting type	PCB connector
---------------	---------------

Material specifications

Color (Housing)	white (RAL 9010)
-----------------	------------------


Dimensions

Dimensional drawing	
Pitch	1.8 mm

Packaging specifications

Type of packaging	packed in cardboard
-------------------	---------------------

Drawings

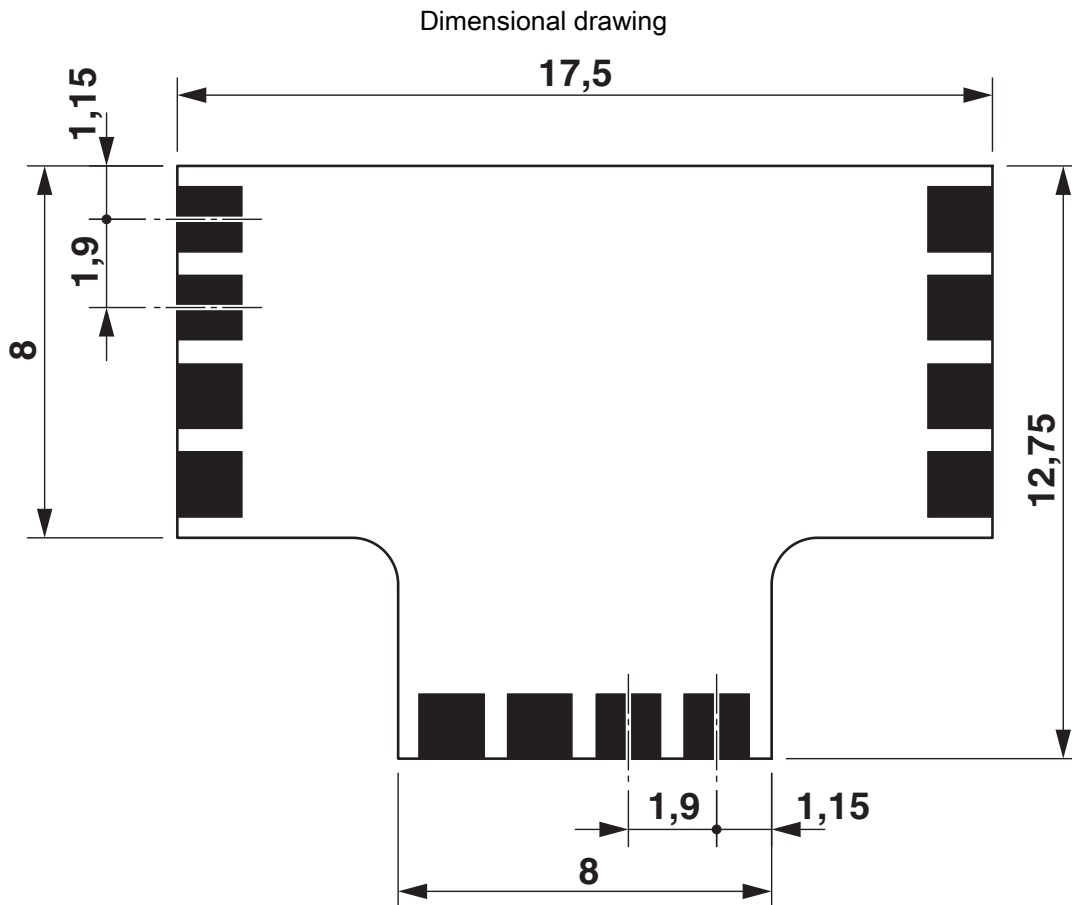

PTF 0,3/ 4-FLEX-T-8 - PCB



1848493

<https://www.phoenixcontact.com/us/products/1848493>

Classifications

ECLASS

ECLASS-11.0	27460201
ECLASS-12.0	27460201
ECLASS-13.0	27460201

ETIM

ETIM 8.0	EC002637
----------	----------

UNSPSC

UNSPSC 21.0	39121400
-------------	----------

PTF 0,3/ 4-FLEX-T-8 - PCB

1848493

<https://www.phoenixcontact.com/us/products/1848493>



Environmental product compliance

EU RoHS

Fulfills EU RoHS substance requirements	Yes, No exemptions
---	--------------------

China RoHS

Environment friendly use period (EFUP)	EFUP-E
	No hazardous substances above the limits

EU REACH SVHC

REACH candidate substance (CAS No.)	No substance above 0.1 wt%
-------------------------------------	----------------------------

PTF 0,3/ 4-FLEX-T-8 - PCB

1848493

<https://www.phoenixcontact.com/us/products/1848493>



Accessories

PTF 0,3/ 2-WB-8-H - Cable set

1707558

<https://www.phoenixcontact.com/us/products/1707558>




Assembled PCB connector, Cable 1: cable length: 0.5 m, Color: red, black,
Cable type:PVC litz wire, PVC litz wire

PTF 0,3/ 4-BB-8-H - PCB connectors

1707559

<https://www.phoenixcontact.com/us/products/1707559>

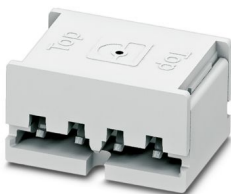

PCB direct plug, nominal cross section: 0.34 mm², color: white, rated voltage (III/2): 25 V, contact surface: Tin, contact connection type: Socket, number of potentials: 4, number of rows: 1, number of positions: 4, number of connections: 4, product range: PTF 0,3/..-BB-H, pitch: 1.9 mm, mounting: Direct plug-in method, plug-in system: COMBICON PTF, type of packaging: packed in cardboard, For flexible PCBs with a width of 8 mm and a permissible PCB thickness in the contact zone of 0.15 mm ... 0.3 mm

PTF 0,3/ 4-FLEX-T-8 - PCB

1848493

<https://www.phoenixcontact.com/us/products/1848493>



PTF 0,3/ 4-WB-8-H - Cable set

1707561

<https://www.phoenixcontact.com/us/products/1707561>



Assembled PCB connector

Phoenix Contact 2024 © - all rights reserved

<https://www.phoenixcontact.com>

Phoenix Contact USA
586 Fulling Mill Road
Middletown, PA 17057, United States
(+717) 944-1300
info@phoenixcon.com