




You are here: [Home](#) ▶ [Magnetic Buzzer](#) ▶ [Magnetic Indicator](#) ▶ [Pin](#) ▶ KXG1606C


KXG1606C

[Print](#)


VOLTAGE-SOUND PRESSURE
LEVEL

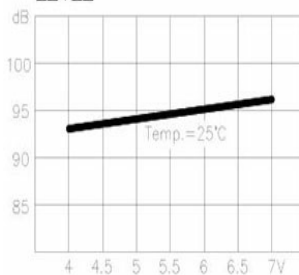

VOLTAGE-CURRENT
CONSUMPTION

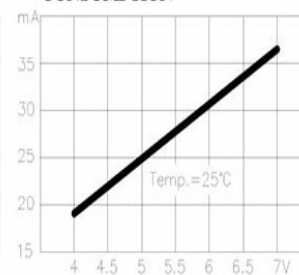

Additional Info

Rated Frequency (Hz):	2,200+/-300
Rated Voltage (Vo-p/VDC):	6.0
Current Consumption (mA):	Max. 50
Sound Pressure Level (dB):	Min. 85dBA(Typical 92)@10cm
Operating Voltage Range (Vo-p):	4.0~7.0
Operating Temperature (°C):	-20~+60
Storage Temperature (°C):	-30~+70
Dimension (mm):	φ16.0x14.0
Sound Demonstration:	click here

 [Like](#) [Sign Up](#) to see what your friends like.

Tagged under [Indicator Pin Internal Circuitry Type 40VDC](#)

More in this category: [« KXG1212C](#) [KXG1612C »](#)

[back to top](#)

