

Push Mount Nylon Cable Ties




Features

- Quick Mounting One Piece-Design Securely Attaches Bundle to Panel
- Extra Stability is Created from the Tensioning Wings
- Thickness Variations in materials is Easily Overcome with Tension Wings



WT-06

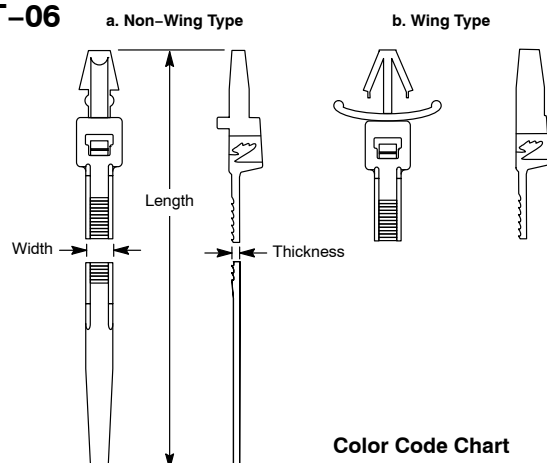

Color Code Chart

0	UV Black	9	Natural
---	----------	---	---------

50 lb. Wing and Non-Wing

NTE Type No.	Length	Width	Thickness	Max. Bundle Dia. (Note 3)	Hole Size	Panel	Qty. per Bag	Diag No.
04-0750PMx	7.9 / 203.0	.189 / 4.80	.062 / 1.574	1.969 / 50.0	.252 / 6.40	.140 / 3.55	100	WT-06a
04-0750PMWx	7.8 / 200.0	.189 / 4.80	.062 / 1.574	1.969 / 50.0	.236 / 6.00	.140 / 3.55	100	WT-06b

Note 1. Replace "x" in device number with corresponding color code from the "Color Code Chart".

Note 2. Dimensions are listed as "inch / millimeter".


Note 3. "Max. Bundle Dia." is defined as the maximum bundle diameter achieved after insertion for 3 "clicks" due to having a 3 tooth pawl.

Hook & Loop Cable Ties




Features

- Rated for Indoor and Outdoor Use
- Hook & Loop Construction Allows for Use Over and Over
- Constructed Using Nylon (Male Side) and Polypropylene (Female Side) Material

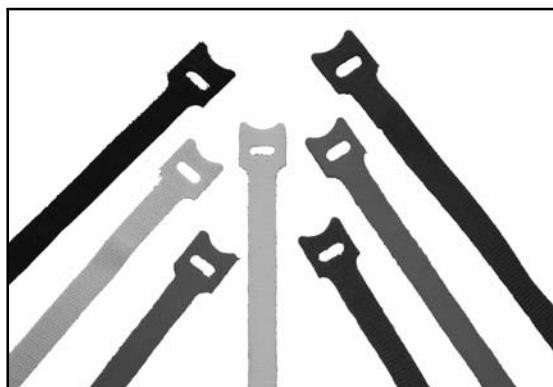

WT-07

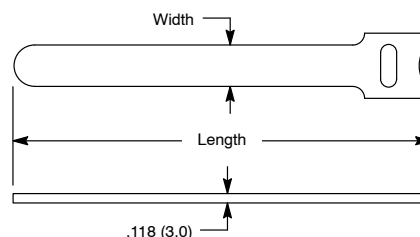

Color Code Chart

0	Black	6	Blue
2	Red	10	White *
4	Yellow	MC	Multi-Color
5	Green		

* Available in 40 lb. 5.91" length ONLY

33 lb. Hook & Loop

NTE Type No.	Length (in. / mm)	Width (in. / mm)	Max. Bundle Dia. (in. / mm)	Qty. per Bag	Diag No.
04-0533HLxx	4.92 / 125.0	.470 / 12.0	1.180 / 30.0	10	WT-07

40 lb. Hook & Loop

NTE Type No.	Length (in. / mm)	Width (in. / mm)	Max. Bundle Dia. (in. / mm)	Qty. per Bag	Diag No.
04-0640HLxx	5.91 / 150.0	.470 / 12.0	1.380 / 35.0	10	WT-07
04-0840HLxx	7.87 / 200.0	.470 / 12.0	1.770 / 45.0	10	WT-07
04-1040HLxx	9.45 / 240.0	.510 / 13.0	2.360 / 60.0	10	WT-07

Note 1. Replace "x" or "xx" in device number with corresponding color code from the "Color Code Chart".