


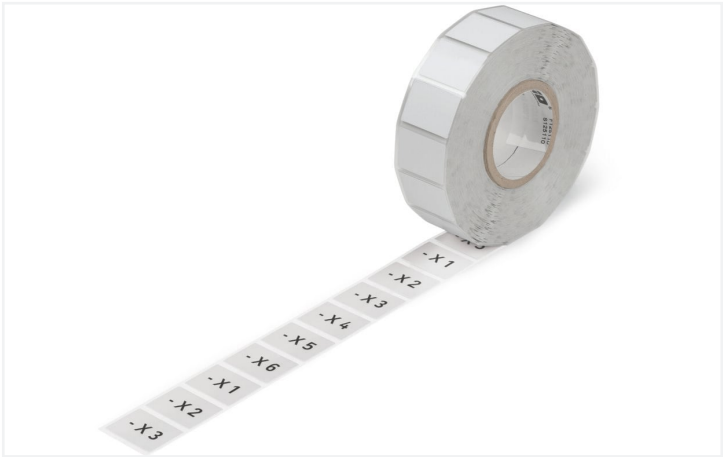

Color: silver-colored Similar to illustration

Technical data	
Suitable	without button frame
Marking method	Thermal transfer
Marking	plain
Delivery form	Roll
Delivery form configuration	300 markers/reel; 1 line
Printing device	Smart Printer (thermal transfer printer)

Physical data	
Height	22 mm
Width	22 mm
Depth	0.09 mm
Marking surface	22 x 22 mm

Mechanical data	
Mounting type	Sticking
Smear resistance	in conjunction with 258-5005 Ink Ribbon

Material data	
Color	silver-colored
Material	Polyester
UV resistance	EN 60068-2-5:2010 Procedure B
Adhesive information	Acrylic; permanent; foamed
Halogen-free	Yes
Weight	92 g
Fire load	0 MJ



Environmental requirements	
Ambient temperature (storage)	≥+22 °C
Ambient temperature (operation)	-30 ... +130 °C
Relative humidity	40 ... 50 %

Commercial data	
eCl@ss 10.0	27-40-06-29
eCl@ss 9.0	27-40-06-29
ETIM 8.0	EC001288
ETIM 7.0	EC001288
PU (SPU)	1 pcs
Packaging type	Box
Country of origin	DE
GTIN	4055143426442
Customs tariff number	39191080888

Environmental Product Compliance	
RoHS Compliance Status	Compliant,No Exemption

Downloads

Environmental Product Compliance

Compliance Search

Environmental Product Compliance 210-847

↓

Documentation

Operating Instructions

210-852 Information on handling print material128.08.2020pdf1004.72 KB

↓

1 Compatible Products

1.1 Optional Accessories

1.1.1 Marking

1.1.1.1 Marking device



Item No.: 258-5000
Thermal transfer printer; Smart Printer; for complete control cabinet marking; 300 dpi; With marking material

Subject to changes. Please also observe the further product documentation!

Current addresses can be found at: www.wago.com