


794137-1 Product Details

[Live Product Chat](#)

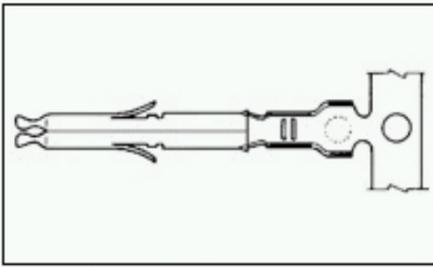

794137-1

TE Part Number: 794137-1

[Active](#)

[Add to Part List](#)

[View 3D PDF](#)

.163" Centerline, 600 V, 9.5 A max.

[Always EU RoHS/ELV Compliant \(Statement of Compliance\)](#)

Product Highlights:

- Contact
- Mini-Universal MATE-N-LOK
- Socket
- Strip
- Wire Range = 0.30-0.90² [22-18] mm [AWG]

[View all Features](#) | [Find Similar Products](#)

Quick Links

- ▶ [Check Pricing & Availability](#)
- ▶ [Search for Tooling](#)
- ▶ [Product Feature Selector](#)
- ▶ [Contact Us About This Product](#)
- ▶ [Request Samples](#)

NEW!

Documentation & Additional Information

Product Drawings:

- [SOCKET, MINI UNIVERSAL MATE-N-LOK\(TM\)](#) (PDF, English)

Catalog Pages/Data Sheets:

- None Available

Product Specifications:

- None Available

Application Specifications:

- [Mini-Universal MATE-N-LOK Connectors](#) (PDF, English)

Instruction Sheets:

- None Available

CAD Files: ([CAD Format & Compression Information](#))

- [2D Drawing](#) (DXF, Version B1)
- [3D Model](#) (IGES, Version B1)
- [3D Model](#) (STEP, Version B1)

[List all Documents](#)

Additional Information:

- [Product Line Information](#)

Related Products:

- [Tooling](#)

Product Features (Please use the Product Drawing for all design activity)

Product Type Features:

- Product Type = Contact
- Connector Line = Mini-Universal MATE-N-LOK
- Gender = Socket
- Wire Insulation Diameter (mm [in]) = 1.50 - 2.40 [0.059 - 0.094]
- Comment = With locking lance.

Electrical Characteristics:

- Voltage (VAC) = 600
- Current Rating (Amps.) = 9.5

Termination Related Features:

- Solder Tail Contact Plating = Pre-Tin

Body Related Features:

- Wire Range (mm [AWG]) = 0.30-0.90² [22-18]
- Contact Diameter (mm [in]) = 0.99 [0.039]
- Stock Thickness (mm [in]) = 0.20 [0.008]

Contact Related Features:

- Contact Material = Brass
- CompactPCI = No

Industry Standards:

- [RoHS/ELV Compliance](#) = RoHS compliant, ELV compliant
- [Lead Free Solder Processes](#) = Not relevant for lead free process
- RoHS/ELV Compliance History = Always was RoHS compliant

Packaging Related Features:

- Packaging Method = Strip
- Packaging Quantity = 7,000

Other:

- Brand = AMP

[Provide Website Feedback](#) | [Need Help?](#)