


Part Number : [428171014](#)

Product Description : Mini-Fit Sr. Crimp Terminal,
Male, 12-10 AWG, Silver (Ag)

Series Number : 42817

Status : Active

Product Category : Crimp Terminals

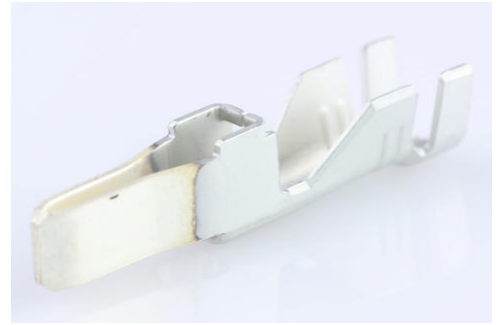

Documents and Resources

Drawings

[428171014 sd.pdf](#)

[STEP AP242](#)

[SOLIDWORKS](#)

[Creo](#)

Specifications

[AS-42815-001-001.pdf](#)

[PS-42815-001-001.pdf](#)

[TS-42815-004-001.pdf](#)

Product Environment Compliance

Compliance

GADSL/IMDS	Compliant with Exemption 44; 33
China RoHS	per SJ/T 11365-2006
EU ELV	Not Relevant
Low-Halogen Status	Low-Halogen per IEC 61249-2-21
REACH SVHC	Not Contained per D(2025)4165-DC (25 June 2025)
EU RoHS	Compliant per EU 2015/863

Compliance Statements

- EU RoHS
- REACH SVHC
- Low-Halogen

Industry Documents

- IPC 1752A Class C
- IPC 1752A Class D

- Molex Product Compliance Declaration
- IEC-62474
- chemSHERPA (xml)

Substances of Interest

- PFAS

EU RoHS Certificate of Compliance

Additional Product Compliance Information

Part Details

General

Status	Active
Category	Crimp Terminals
Series	42817
Description	Mini-Fit Sr. Crimp Terminal, Male, 12-10 AWG, Silver (Ag)
Application	Wire-to-Wire
Comments	High Current/Low Force; See Product Specification for maximum current rating by circuit size and application.
Product Name	Mini-Fit Sr.
UPC	889056244749

Electrical

Current - Maximum per Contact	50.0A
-------------------------------	-------

Physical

Gender	Male
Material - Metal	High Performance Alloy (HPA)
Material - Plating Mating	Silver
Material - Plating Termination	Tin
Net Weight	1.395/g
Packaging Type	Reel
Plating min - Mating	2.540µm
Plating min - Termination	2.540µm
Termination Interface Style	Crimp or Compression

Wire Insulation Diameter	5.30mm max.
Wire Size (AWG)	10, 12
Wire Size mm ²	N/A

Solder Process Data

Lead-Free Process Capability	N/A
------------------------------	-----

Mates With / Use With

Use with Part(s)

Description	Part Number
10.00mm Pitch Mini-Fit Sr. Single Row Plug Housings	<u>42818</u>
Mini-Fit Sr. Dual Row Plug Housings	<u>43938</u>

Application Tooling

Global

Description	Part Number
Hand Crimp Tool for Mini-Fit Sr. Crimp Terminals, 12-10 AWG	<u>2002181600</u>
FineAdjust Applicator for Insulation OD 4.40-5.30mm, 12-10 AWG	<u>2037022700</u>
FineAdjust Applicator for Insulation OD 3.50-4.40mm, 12-10 AWG	<u>2037022800</u>
Extraction Tool for Mini-Fit Sr. Terminals, 16-8 AWG	<u>638130400</u>
Hand Crimp Tool for 10.00mm Pitch Mini-Fit Sr. Crimp Terminals, 12-10 AWG	<u>2133099700</u>

This document was generated on Jul 06, 2026