

Fittings with fixed external thread

- HGL-S Straight, IP68

TYPE	Nominal Ø	Thread Size	Min. Bore Size (B)	Outside Ø max (OD max.)	Length (L)	A/F Body (A/F1)	Thread Length (TL)	Pack Cont.	Colour	Article-No.
HGL42-S-M40	42	M40	32.5	63	61	60	16	2 pcs.	Black (BK)	166-21606
HGL42-S-M50	42	M50	40.5	63	61	73	16	2 pcs.	Black (BK)	166-21621
HGL42-S-PG36	42	PG36	40.0	63	56	60	12	2 pcs.	Black (BK)	166-21614
HGL54-S-M50	54	M50	42.0	76	65	73	16	2 pcs.	Black (BK)	166-21607
HGL54-S-M63	54	M63	53.0	76	65	73	16	2 pcs.	Black (BK)	166-21622
HGL54-S-PG42	54	PG42	47.0	76	61	73	12	2 pcs.	Black (BK)	166-21628
HGL54-S-PG48	54	PG48	52.0	76	61	73	12	2 pcs.	Black (BK)	166-21616

All dimensions in mm. Subject to technical changes. Colour grey available on request. Minimum Order Quantity (MOQ) may differ from package content.

Fittings with fixed external thread

- HG-90 90° Elbow, IP66


90° elbow external thread.

Features and Benefits

- One piece, fast fit
- High pull-off strength
- Highly resistant to solvents and oils
- Free of halogen, sulphur and phosphorus
- Metric threads supplied with locknuts



HelaGuard HG-90 90° Elbow, IP66.

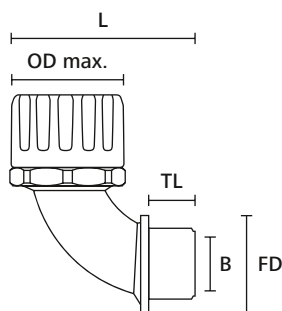

HelaGuard fitting, 90° with fixed external thread

MATERIAL	Polyamide 6.6 (PA66)
Operating Temperature	-50 °C to +135 °C
Flammability	UL94 V2
Specifications	UL-Recognised

HF ✓

RoHS ✓

Fittings with UNEF and NPT threads available on request. Please contact us!

TYPE	Nominal Ø	Thread Size	Min. Bore Size (B)	Outside Ø max (OD max.)	Length (L)	Face Diameter (FD)	Thread Length (TL)	Pack Cont.	Colour	Article-No.
HG10-90-M12	10	M12	6.5	19	32	17	8	10 pcs.	Black (BK)	166-22200
HG10-90-PG7	10	PG7	6.5	19	32	16	8	10 pcs.	Black (BK)	166-22210
HG11-90-M12	11	M12	6.5	19	32	17	8	10 pcs.	Black (BK)	166-22220
HG13-90-M16	13	M16	10.5	24	46	22	11	10 pcs.	Black (BK)	166-22201
HG13-90-PG9	13	PG9	10.5	24	46	22	10	10 pcs.	Black (BK)	166-22211


All dimensions in mm. Subject to technical changes.

Colour grey available on request. Minimum Order Quantity (MOQ) may differ from package content.



Fittings with fixed external thread

- HG-90 90° Elbow, IP66

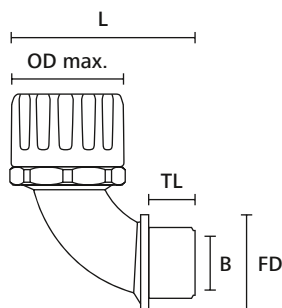

HelaGuard fitting, 90° with fixed external thread

TYPE	Nominal Ø	Thread Size	Min. Bore Size (B)	Outside Ø max (OD max.)	Length (L)	Face Diameter (FD)	Thread Length (TL)	Pack Cont.	Colour	Article-No.
HG16-90-M16	16	M16	10.5	29	49	22	11	10 pcs.	Black (BK)	166-22202
HG16-90-M20	16	M20	14.0	29	51	27	13	10 pcs.	Black (BK)	166-22203
HG16-90-PG9	16	PG9	10.5	29	49	22	10	10 pcs.	Black (BK)	166-22225
HG16-90-PG11	16	PG11	10.5	29	49	24	10	10 pcs.	Black (BK)	166-22212
HG16-90-PG13	16	PG13.5	14.0	29	51	26	11	10 pcs.	Black (BK)	166-22213
HG21-90-M20	21	M20	14.0	32	53	27	13	10 pcs.	Black (BK)	166-22204
HG21-90-PG13	21	PG13.5	14.0	32	53	26	11	10 pcs.	Black (BK)	166-22227
HG21-90-PG16	21	PG16	14.0	32	53	27	11	10 pcs.	Black (BK)	166-22214
HG25-90-M25	25	M25	19.0	39	63	32	15	10 pcs.	Black (BK)	166-22222
HG28-90-M25	28	M25	19.0	44	66	32	15	10 pcs.	Black (BK)	166-22205
HG28-90-PG21	28	PG21	19.0	44	66	35	12	10 pcs.	Black (BK)	166-22215
HG34-90-M32	34	M32	24.5	51	75	40	16	10 pcs.	Black (BK)	166-22206
HG34-90-PG29	34	PG29	24.5	51	75	44	12	10 pcs.	Black (BK)	166-22216
HG42-90-M40	42	M40	32.5	63	98	50	16	2 pcs.	Black (BK)	166-22207
HG42-90-M50	42	M50	39.0	63	99	60	16	2 pcs.	Black (BK)	166-22223
HG42-90-PG36	42	PG36	39.0	63	99	57	12	2 pcs.	Black (BK)	166-22217
HG54-90-M50	54	M50	39.0	76	104	60	16	2 pcs.	Black (BK)	166-22208
HG54-90-M63	54	M63	49.5	76	104	72	16	2 pcs.	Black (BK)	166-22224
HG54-90-PG48	54	PG48	49.5	76	104	70	15	2 pcs.	Black (BK)	166-22218
HG67-90-M63	67	M63	49.5	90	120	72	16	1 pcs.	Black (BK)	166-22209
HG67-90-PG48	67	PG48	49.5	90	120	70	15	1 pcs.	Black (BK)	166-22219

All dimensions in mm. Subject to technical changes.

Colour grey available on request. Minimum Order Quantity (MOQ) may differ from package content.



Please note! Not all products listed on this page may have this approval.