


Conductor marker - UC-WMC 7,5 (23X8) VT - 0825376

Please be informed that the data shown in this PDF Document is generated from our Online Catalog. Please find the complete data in the user's documentation. Our General Terms of Use for Downloads are valid (<http://phoenixcontact.com/download>)

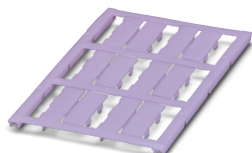

Conductor marker, Sheet, violet, unlabeled, can be labeled with: BLUEMARK ID COLOR, BLUEMARK ID, BLUEMARK CLED, PLOTMARK, CMS-P1-PLOTTER, mounting type: clip on, cable diameter range: 5 ... 7.5 mm, lettering field size: 23 x 8 mm, Number of individual labels: 6

Your advantages

- ✓ The UC-WMC ... UniCard labeling range includes markers for captive labeling of control lines to cable sheaths with large diameters
- ✓ The markers, which are supplied in uniform sheets, can be labeled quickly and easily using the BLUEMARK LED
- ✓ The sheets provide space for including function texts
- ✓ The format automatically ensures printing with a high degree of positioning accuracy
- ✓ The markers support multi-line labeling
- ✓ One-handed mounting
- ✓ Labeling service: Phoenix Contact can custom-label all UniCard markers according to your requirements
- ✓ Two labeling areas that are clearly legible at all times
- ✓ Can be clipped on even after wiring has been completed

RoHS

Key Commercial Data

Packing unit	1 pc
Minimum order quantity	5 pc
GTIN	 4 046356 350488
GTIN	4046356350488
Weight per Piece (excluding packing)	14.640 g
Custom tariff number	39269097
Country of origin	Poland

Technical data

Dimensions

Conductor marker - UC-WMC 7,5 (23X8) VT - 0825376

Technical data

Dimensions

Length (b)	23 mm
Width (a)	8 mm
Cable diameter	5 mm ... 7.5 mm

Ambient conditions

Ambient temperature (operation)	-40 °C ... 120 °C
---------------------------------	-------------------

General

Color	violet
Type	Card form
Components	free from silicone and halogen
Material	PA
Flammability rating according to UL 94	V2
Wipe resistance	DIN EN 61010-1 (VDE 0411-1)
Number of individual labels	6
Number of individual labels per row	2
Mounting type	clip on
Min. cross section	6 mm ²
Max. cross section	16 mm ²
AWG min	10
AWG max	6
Fire protection for rail vehicles (DIN EN 45545-2) R22	HL 1 - HL 2
Fire protection for rail vehicles (DIN EN 45545-2) R23	HL 1 - HL 2
Fire protection for rail vehicles (DIN EN 45545-2) R24	HL 1 - HL 2
Testing substances harmful to the wetting properties of lacquers (LABS conformity)	VW PV 3.10.7:2005-02
Result	Test passed
UV resistance	Following ISO 4892-2:2013-03
Result	Test passed
Test duration	96 h
Test for wipe resistance of inscriptions	DIN EN 61010-1 (VDE 0411-1):2011-07
	DIN EN 62208 (VDE 0660-511):2012-06 (in parts)
Testing in a condensation changing climate in the presence of sulfur dioxide	DIN 50018:2013-05
Result	Test passed
Climate level	AHT 1,0 S
Cycles	2
Salt spray test	DIN EN 60068-2-11:2000-02
Result	Test passed

Conductor marker - UC-WMC 7,5 (23X8) VT - 0825376

Technical data

Environmental Product Compliance

China RoHS	For details about hazardous substances go to tab "Downloads", Category "Manufacturer's declaration"
------------	---

Drawings

Pictogram



Classifications

eCl@ss

eCl@ss 10.0.1	27400401
eCl@ss 11.0	27281102
eCl@ss 4.0	27061700
eCl@ss 4.1	27061700
eCl@ss 5.0	27149100
eCl@ss 5.1	27400400
eCl@ss 6.0	27149100
eCl@ss 7.0	27149129
eCl@ss 9.0	27400401

ETIM

ETIM 2.0	EC000761
ETIM 3.0	EC000761
ETIM 4.0	EC000761
ETIM 6.0	EC001530
ETIM 7.0	EC001530

UNSPSC

UNSPSC 6.01	30211811
UNSPSC 7.0901	39121410
UNSPSC 11	39121410
UNSPSC 12.01	39121410
UNSPSC 13.2	39131504
UNSPSC 18.0	39131504
UNSPSC 19.0	39131504
UNSPSC 20.0	39131504
UNSPSC 21.0	39131504

Conductor marker - UC-WMC 7,5 (23X8) VT - 0825376

Accessories

Accessories

Magazine

Magazine - P1 UC-MAG 3 - 5146095



Magazine, for CMS-P1-PLOTTER, for accommodating UC-WMC 7,5...

Printing system accessories

Ink cartridge - BLUEMARK CLED-FLUID-CARTR. - 5146662



Cartridge, for replacement, 20 ml UV color, black, including cleaning cartridge

Ink cartridge - BLUEMARK FLUID-CARTRIDGE - 5147421



Cartridge, for replacement, 28 ml UV color, black including cleaning cartridge

Ink cartridge - BM ID-CARTR. BK - 1044345



Replacement UV fluid, 23 ml, color: black

Conductor marker - UC-WMC 7,5 (23X8) VT - 0825376

Accessories

Ink cartridge - BM ID-CARTR. CY - 1044346



Replacement UV fluid, 23 ml, color: cyan

Ink cartridge - BM ID-CARTR. MA - 1044347



Replacement UV fluid, 23 ml, color: magenta

Ink cartridge - BM ID-CARTR. YE - 1044348



Replacement UV fluid, 23 ml, color: yellow
