



Shrinkable markers "Continuous Tube", thermal transfer

TULT - 3:1 Military and Electronics

TULT is a UL recognized 3:1 heatshrink material supplied as a continuous tube and printable on both sides. The supplied accessories allow users to either perforate the tubing at pre-determined lengths (P4000), or fully sever the markers (S4000) whilst printing with the TrakMark DS or TT4000+ printer. Print with HellermannTyton's premium range of thermal printers and ribbons.

Printers: TrakMark DS, TT4000+ and TT430

Ribbons: TTRC+, TTDTHOUT, TTRW, TT822OUT8


Accessories for TrakMark DS and TT4000+: Perforator (P4000), Cutter (S4000)

Accessories for TT430: Cutter (S430), Perforator (P430)

Software: TagPrint Pro

Features and Benefits

- Shrink ratio 3:1
- Available in black, blue, red, white and yellow
- Cable range from 39 mm to 1 mm
- Good mechanical strength and resistance to organic solvents and chemicals
- Highly flexible
- Fulfils UL224 VW-1 and CSA requirements
- Delivery in convenient storage boxes
- Easy label design with TagPrint Pro

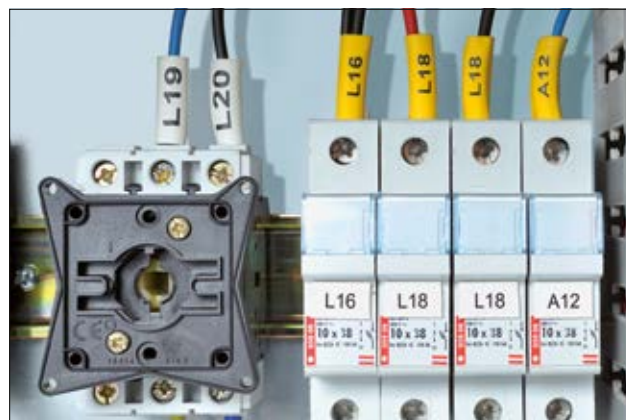

TULT – 5 colours of UL recognised printable tube to cover a wide range of diameters.

MATERIAL	Polyolefin, cross-linked (PO-X)
Operating Temperature	-55 °C to +135 °C
Minimum Shrink Temperature	+90 °C
Shrink Ratio	3:1
Recommended Ribbon Type	TTRC+, TTDTHOUT, TTRW, TT822OUT8
Specifications	CSA, UL-Recognised

RoHS ✓



TYPE	Supplied Ø D min.	Recov. Ø d max.	Wall (WT)	Pack Cont.	Colour	Article-No.
TULT3-1BK	3.0	1.0	0.60	176 m	Black (BK)	553-40300
TULT3-1BU	3.0	1.0	0.60	176 m	Blue (BU)	553-40306
TULT3-1RD	3.0	1.0	0.60	176 m	Red (RD)	553-40302
TULT3-1WH	3.0	1.0	0.60	176 m	White (WH)	553-40309
TULT3-1YE	3.0	1.0	0.60	176 m	Yellow (YE)	553-40304
TULT4.8-1.6BK	4.8	1.6	0.65	110 m	Black (BK)	553-40480
TULT4.8-1.6BU	4.8	1.6	0.65	110 m	Blue (BU)	553-40486
TULT4.8-1.6RD	4.8	1.6	0.65	110 m	Red (RD)	553-40482
TULT4.8-1.6WH	4.8	1.6	0.65	110 m	White (WH)	553-40489
TULT4.8-1.6YE	4.8	1.6	0.65	110 m	Yellow (YE)	553-40484
TULT6-2BK	6.0	2.0	0.70	110 m	Black (BK)	553-40600
TULT6-2BU	6.0	2.0	0.70	110 m	Blue (BU)	553-40606
TULT6-2RD	6.0	2.0	0.70	110 m	Red (RD)	553-40602
TULT6-2WH	6.0	2.0	0.70	110 m	White (WH)	553-40609

All dimensions in mm. Subject to technical changes.

Minimum Order Quantity (MOQ) may differ from package content.



For product specific approvals and specifications please refer to the Appendix.

Shrinkable markers "Continuous Tube", thermal transfer

TULT - 3:1 Military and Electronics



TYPE	Supplied Ø D min.	Recov. Ø d max.	Wall (WT)	Pack Cont.	Colour	Article-No.
TULT6-2YE	6.0	2.0	0.70	110 m	Yellow (YE)	553-40604
TULT9-3BK	9.0	3.0	0.80	72 m	Black (BK)	553-40900
TULT9-3BU	9.0	3.0	0.80	72 m	Blue (BU)	553-40906
TULT9-3RD	9.0	3.0	0.80	72 m	Red (RD)	553-40902
TULT9-3WH	9.0	3.0	0.80	72 m	White (WH)	553-40909
TULT9-3YE	9.0	3.0	0.80	72 m	Yellow (YE)	553-40904
TULT12-4BK	12.0	4.0	0.85	54 m	Black (BK)	553-41200
TULT12-4BU	12.0	4.0	0.85	54 m	Blue (BU)	553-41206
TULT12-4RD	12.0	4.0	0.85	54 m	Red (RD)	553-41202
TULT12-4WH	12.0	4.0	0.85	54 m	White (WH)	553-41209
TULT12-4YE	12.0	4.0	0.85	54 m	Yellow (YE)	553-41204
TULT18-6BK	18.0	6.0	1.00	26 m	Black (BK)	553-41800
TULT18-6BU	18.0	6.0	1.00	26 m	Blue (BU)	553-41806
TULT18-6RD	18.0	6.0	1.00	26 m	Red (RD)	553-41802
TULT18-6WH	18.0	6.0	1.00	26 m	White (WH)	553-41809
TULT18-6YE	18.0	6.0	1.00	26 m	Yellow (YE)	553-41804
TULT24-8BK	24.0	8.0	1.20	26 m	Black (BK)	553-42400
TULT24-8BU	24.0	8.0	1.20	26 m	Blue (BU)	553-42406
TULT24-8RD	24.0	8.0	1.20	26 m	Red (RD)	553-42402
TULT24-8WH	24.0	8.0	1.20	26 m	White (WH)	553-42409
TULT24-8YE	24.0	8.0	1.20	26 m	Yellow (YE)	553-42404
TULT39-13BK	39.0	13.0	1.25	10 m	Black (BK)	553-43900
TULT39-13BU	39.0	13.0	1.25	10 m	Blue (BU)	553-43906
TULT39-13RD	39.0	13.0	1.25	10 m	Red (RD)	553-43902
TULT39-13WH	39.0	13.0	1.25	10 m	White (WH)	553-43909
TULT39-13YE	39.0	13.0	1.25	10 m	Yellow (YE)	553-43904

All dimensions in mm. Subject to technical changes.
Minimum Order Quantity (MOQ) may differ from package content.



For product specific approvals and specifications please refer to the Appendix.