




[+ HARNESSING](#)
[HEAT SHRINK BOOTS](#)

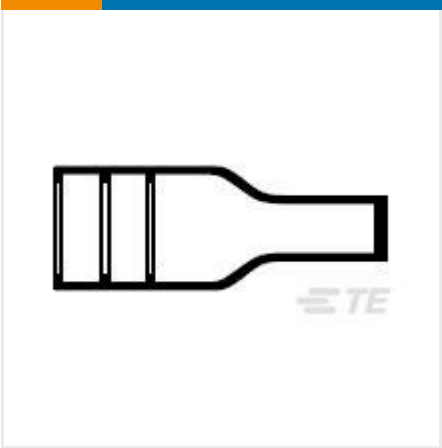

✓ Active

TE CONNECTIVITY (TE)
202D121-25-0
[Raychem](#) | [CAP](#) , [CRPS](#)

202D121-25-0
TE Internal Number: 814344-000
Alias ID: 9-1196338-6

[EU RoHS Compliant](#)
[EU ELV Compliant](#)

Lipped Yes

Operating Temperature Range (°C) -75 – 150

Adhesive Options None

Material Systems Code 25

Adhesive Pre-Coat No

[↓](#) **PRODUCT DRAWING**
English

DOCUMENTATION

Product Drawings

Boot, Straight, With Lips
PDF
English

Product Specifications

Product Specification

Thermofit Elastomeric Molded Components Flame-Retarded, Semi-Rigid, Heat-Shrinkable
PDF
English

-25 MOULDED PARTS
PDF
English

Product Environmental Compliance

Safety Data Sheet

EPS Heat Shrinkable Polymeric Products

PDF

French

EPS Heat Shrinkable Polymeric Products

PDF

Italian

EPS Heat Shrinkable Polymeric Products

PDF

Dutch

EPS Heat Shrinkable Polymeric Products

PDF

Danish

EPS Heat Shrinkable Polymeric Products

PDF

English

EPS Heat Shrinkable Polymeric Products

PDF

German

EPS Heat Shrinkable Polymeric Products

PDF

Norwegian

EPS Heat Shrinkable Polymeric Products

PDF

Spanish

EPS Heat Shrinkable Polymeric Products

PDF

Swedish

FEATURES



Please review product documents or [contact us](#) for the latest agency approval information.

Please Note: Use the Product Drawing for all design activity.

Product Type Features

Molded Part Type Molded Boot

Configuration Features

Lipped Yes

Body Features

Material Systems Code 25
Adhesive Pre-Coat No
Material Modified Elastomer

Dimensions

Inside Diameter as Supplied 23.4 mm [.92 in]

Usage Conditions

Operating Temperature Range (°C) -75 – 150

Operation/Application

Power Cable Accessory No

Industry Standards

Government Qualified No
Approved Standards VG95343 Parts 6,7,8 and 9

Other

Adhesive Options None
Adhesive Type Adhesive Purchased Separately

Statement of Compliance

Statement of Compliance
PDF