




+ CONNECTORS
RF CONNECTORS

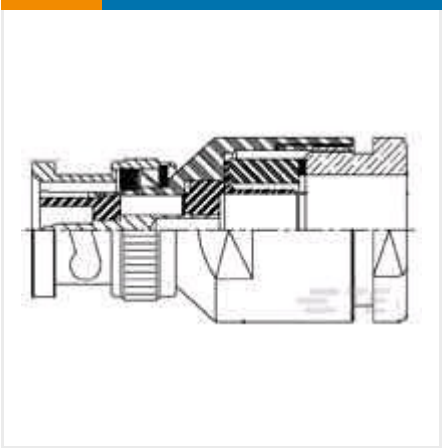

✓ Active

TE CONNECTIVITY (TE)
BNC Str Plg PS 75Ohm Silver RG59B/U, 62A
Miniature Coax | STA , U

1-1478404-0
TE Internal Number: 1-1478404-0

EU RoHS Compliant with Exemptions
EU ELV Compliant with Exemptions

Connector Interface BNC

Connector Style Plug

Mated Outer Diameter (Approximate) 14.529 mm [.572 in]

Impedance (Ω) 75

Cable Type PSF 1/3M, Raychem 9524A1311, Raychem 9524A1811, RG 140, RG 210, RG 59B, URM 90

DOCUMENTATION

Product Drawings

BNC STRAIGHT PLUG SOLDER (PS) 59U 75 Ohm

TIF
English

Instruction Sheets

Instruction Sheet (non U.S.)

GREENPAR RF CONNECTOR CABLE ASSEMBLY INSTRUCTION SHEET

PDF
English

GREENPAR RF CONNECTOR CABLE ASSEMBLY INSTRUCTION SHEET

TIF
English

FEATURES



Please review product documents or [contact us](#) for the latest agency approval information.

Product Type Features

- Connector Interface** BNC
- Connector Style** Plug
- Sealable** No
- Connector & Contact Terminates To** Wire & Cable

Configuration Features

- Number of Positions** 1

Electrical Characteristics

- Impedance (Ω)** 75

Body Features

- Cable Connector Orientation** Straight
- Body Material** Brass
- Body Plating Material** Silver
- Body Insulation** Without

Contact Features

- Center Contact Plating Material** Silver
- Center Contact Material** Brass

Termination Features

- Termination Method to Wire & Cable** Clamp, Solder Terminal

Dimensions

- Mated Outer Diameter (Approximate)** 14.529 mm [.572 in]

Usage Conditions

- Cable Type** PSF 1/3M, Raychem 9524A1311, Raychem 9524A1811, RG 140, RG 210, RG 59B, URM 90

Operation/Application

- Operating Frequency (GHz)** 2

Packaging Features

- Packaging Method** Box
- Packaging Quantity** 50

Other

Dielectric Material PTFE
Gasket Material Silicone Rubber
Coupling Nut Material Brass
Grade Professional

PRODUCT COMPLIANCE

+

Statement of Compliance

Statement of Compliance
PDF

