



Color: ■ gray

Similar to illustration

### Electrical data

#### Ratings per IEC/EN

Rated current	16 A
---------------	------

### Physical data

Width	10 mm / 0.394 inches
Height	10 mm / 0.394 inches
Depth	4 mm / 0.157 inches
Jumper assignment	1-2

### Material data

Note (material data)	<a href="#">Information on material specifications can be found here</a>
Color	gray
Material group	I
Insulation material (main housing)	Polyamide (PA66)
Flammability class per UL94	V0
Fire load	0.007 MJ
Weight	0.6 g

**Environmental requirements**

Processing temperature	-35 ... +85 °C
Continuous operating temperature	-60 ... +105 °C

**Commercial data**

Product Group	9 (Std Chassis Mt Blocks)
PU (SPU)	500 (25) pcs
Packaging type	Box
Country of origin	PL
GTIN	4045454033736
Customs tariff number	85366990990

**Product Classification**

UNSPSC	39121410
eCl@ss 10.0	27-14-11-40
eCl@ss 9.0	27-14-11-40
ETIM 9.0	EC000489
ETIM 10.0	EC000489
ECCN	NO US CLASSIFICATION

**Environmental Product Compliance**

RoHS Compliance Status	Compliant, No Exemption
------------------------	-------------------------

**Downloads**

**Environmental Product Compliance**

<b>Compliance Search</b>	
Environmental Product Compliance 261-402	

**Documentation**

<b>Bid Text</b>			
261-402	19.02.2019	xml 2.62 KB	
261-402	17.08.2017	doc 23.50 KB	

## CAD/CAE-Data

### CAD data

2D/3D Models 261-402



### CAE data

EPLAN Data Portal  
261-402



WSCAD Universe  
261-402



ZUKEN Portal 261-402



## 1 Compatible Products

### 1.1 Optional Accessories

#### 1.1.1 Tool

##### 1.1.1.1 Operating tool




**Item No.: 209-132**

Operating tool; for connecting comb-style jumper bar; made of insulating material; 2-way; natural

## Installation Notes

### Commoning

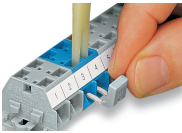

Commoning with comb-style jumper bar.