


[Labels](#) / [Labels by Portable Printer](#) / [TLS PC Link Labels](#) /

BMP61 BMP71 TLS 2200 UltraTemp 1-Mil Matte Polyimide Labels

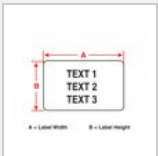

BMP61 BMP71 TLS 2200 UltraTemp 1-Mil Matte Polyimide Labels

Part Number:

PTL-28-719

Label/Tape Size:

0.25 in H x 1.5 in W

Material:

Polyimide

For Use with Printer:

BMP®61 Labeling System, BMP®71 Label
Printer, TLS 2200® Thermal Labeling
System, TLS-PC LINK™ Thermal Labeling
System

Color:

White

Material Number:

B-719

ADD TO CART

1



Add To Favorites

PEOPLE ALSO VIEWED

OVERVIEW

Static Dissipative Polyimide (B-719) withstands wave solder environments and multiple harsh washes for printed circuit board and electronic component preprocess labeling.

- Low profile, high temperature, matte white polyimide material features a static dissipative adhesive and static dissipative release liner
- Surface resistivity values in the recommended range for Dissipative ESD packaging materials as defined by ANSI/ESD S541-2008
- RoHS compliant to 2011/65/EU; UL Approved; Meets requirements of MIL-STD-202G, Method 215K
- Service temperature of -94 to 212° F (-70 to 100° C)

SPECIFICATIONS

Material Number

B-719

Dimensions	0.25 in H x 1.5 in W
UOM	Roll
Finish	Matte
Label/Tape Size	0.25 in H x 1.5 in W
Maximum Service Temperature °F	572 °F
Minimum Service Temperature °F	-94 °F
Pre-Printed Areas on Label	Colored Write-On Area
Product Number	134297
UPC	754473924799
Quantity per Roll	750
Quantity per Row	1
Thickness	0.0033 in
Adhesive Type	Acrylic
Color	White
For Use with Printer	BMP®61 Labeling System, BMP®71 Label Printer, TLS 2200® Thermal Labeling System, TLS-PC LINK™ Thermal Labeling System
Header	No Header
Label/Media Format	Roll
Label Properties	Heat Resistant Labels, Permanent Adhesive Labels
Material	Polyimide
Material Properties	Low Profile, Static-dissipative
Print Technology	Thermal Transfer
Shape	Rectangle
Suggested Ribbon Series	R6000

Solutions

[Floor Marking Guide](#)

Services

[Lockout Tagout Services](#)

Help

[Contact Us](#)

Resources

[Find a Distributor](#)

GHS Label Compliance
Lockout Tagout Compliance
Arc Flash Labeling Requirements
Cable and Wire Label Options
Product and Barcode Labeling
Brand Protection Solutions


Arc Flash Services
Confined Space Services
Visual Workplace Services
Hazcom GHS Services
Software Programming & Integration
Label Template & File Conversion
Printer Use & Training
Printer Preventative Maintenance
Toll and Custom Coating
Authentication & Tracking Services

Knowledge Center
Printer Drivers & Firmware
Brady Software Updates
Safety Data Sheets
Technical Data Sheets
WEEE-RoHS Compliance
Product Certification
Printer Registration

Design Custom Safety Signs
Printer Selection Tool
Label Selection Tool
Digital Catalog
Request a Catalog
Interactive Facility Map
EPA e-Manifest Update

Corporate	Other Brady	Contact
About	Sites	
Careers	Distributor	6555 W.
Investors	Portal	Good Hope
Privacy	International	Rd.
Policy	Sites	Milwaukee,
Terms and	Safety	WI 53223
Conditions	Services &	Phone: 888-
Terms of	Software	250-3082
Use	Smart ID	Hours: 7am-
ISO	Brand	6pm CT
Certificates	Protection	Monday -
	Solutions	Thursday;
		Friday 7am-
		5pm CT

Brady (NYSE:BRC) is a manufacturer of complete solutions that identify and protect people, products and places. Brady's products help customers increase safety, security, productivity and performance and include high-performance labels, signs, safety devices, printing systems and software.

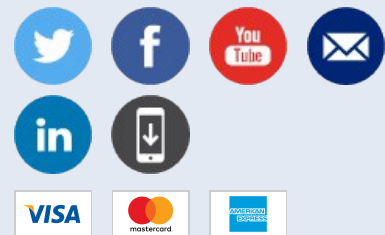

2018 © Brady Worldwide, Inc.