



Search Results

- Evaluate
- Advertisements
 - PDFSetting the
 - FAQ's
 - Product Bulletins
 - PDFType NNC- H ..
- Design a Solution
- Part Drawings
 - PDFType NNC-Ha ..
 - DWG-Wiring Duct ..
 - DXF-Type NNC-Ha ..
 - DXF-Wiring Duct ..
 - DWG-Type NNC-Ha ..
- How to Buy
- Bill of Material
 - Favorite Products List
 - Locate Distributor


Home > Products Overview > Search Results >

Current refinements (click to remove) Search Tips Within Results

Text Search: 'NNC50X100LG2'

Your search criteria matched only one product, shown below

NNC50X100LG2

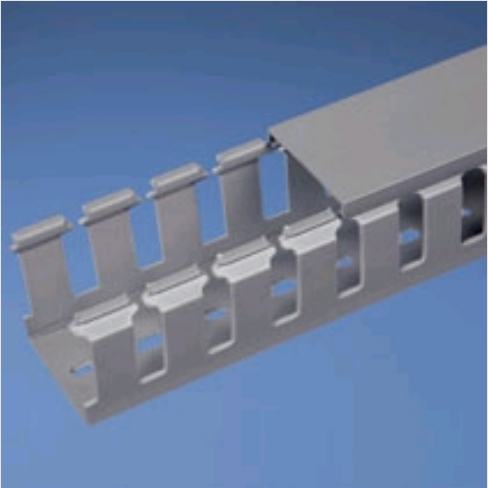

Specifications

- Made of halogen -free modified PPO material and verified with IEC 60754 -2 test method (test on gases evolved during combustion of electric cabling)
- UL Recognized continuous use temperature: 203°F (95°C)
- UL94 Flammability Rating of V -0
- Conforms with NFPA 79 -2002 section 14.3.1 requirement for flame retardant material
- Provided with DIN 43 659 mounting holes
- Metric sizing and finger progression
- Duct and cover packaged together in 2 meter lengths

Features and Benefits

- Halogen -free material eliminates safety and environmental concerns associated with halogenated materials
- UL94V-0 material is self -extinguishing and exhibits the highest flame retardance meeting more electrical panel applications

- Halogen -free non-slip cover liner allows the cover to stay in place during shipment, vibration and when in a vertical orientation, eliminating rework
- DIN 43 659 mounting hole pattern meets European standards for use in cabinet applications
- *PANDUIT* exclusive rounded edges protects hands and wiring/cabling from abrasion
- Double scoreline allows quick modification for larger cabling bundles saving installation time leading to a lower installed cost
- Double restricted slot design retains wire in slot for fast, easy wire installation or removal

DO NOT allow cutting, tapping or cleaning fluids that contain hydrocarbons to come in contact with Type NNC Wiring Duct as it will cause stress cracking.

Base and cover together.

Part Number	NNC50X100LG2
RoHS Compliancy Status	Compliant
Part Description	Halogen-free wiring duct.
Material	Halogen-free Modified PPO
Color	Light Gray
UL Recognized (File No. E147128)	Yes
Length (ft.)	6.56
Length (m)	2
CE Marking	Yes
Duct Size W x H (In.)	1.95 x 3.85
Duct Size W x H (mm)	49.5 x 97.8
Pricing Description	Slotted Duct, Halogen Free,50mm x 100mm x 2M,Light Gray
Slot Width (In.)	.39
Slot Width (mm)	10.0
Cover Part Number	NC50LG2
Min. Order UOM	MR
Min. Order Qty.	10
BOM Qty. (# of Pkgs.)	0
Add to Favorite Product List	

Please [register](#) to utilize the 'Bill of Materials', 'Submit Quotes' and 'Favorite Product List' features.