


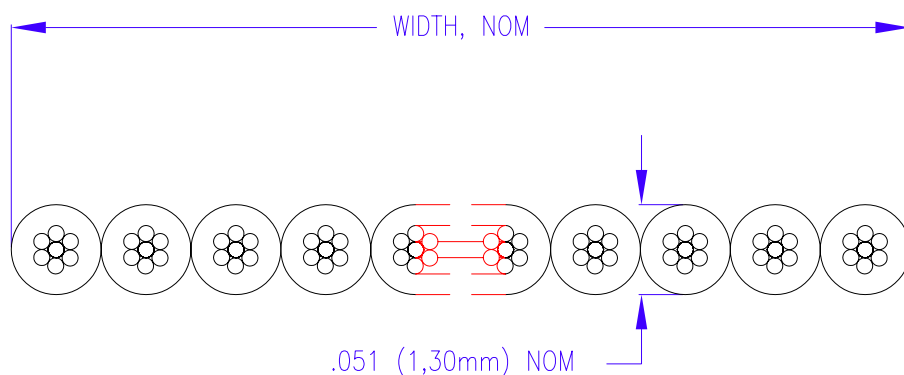

Part Number	Count	Width, Nominal	
111-2213-010	10	.51	(12,94mm)
111-2213-015	15	.77	(19,43mm)
111-2213-018	18	.918	(23,32mm)
111-2213-020	20	1.02	(25,91mm)
111-2213-030	30	1.53	(38,86mm)
111-2213-032	32	1.632	(41,45mm)
111-2213-036	36	1.836	(46,63mm)
111-2213-037	37	1.887	(47,93mm)

PHYSICAL

Conductors: 22 AWG 7/30 Tinned Copper
 Insulation: .010" Nom. PVC
 Color Code: Brown, Red, Orange, Yellow, Green, Blue, Violet, Gray, White, Black and Repeat
 Temp. Rating: 105°C

ELECTRICAL

Voltage Rating: 300 V
 Current Rating: 3.0 A @ 10°C Rise Above Ambient
 Insulation Res.: 10^{10} ohms - 10 ft Min.
 Cable Style: UL AWM Style 2693 (105°C, 300V)

REVISION	CHANGES
D	ADD 36 CNDTR TO DRAWING
C	ADD 18 and 37 CNDTR INTO DRAWING
B	CORRECT 20 CNDTR P/N
A	RELEASE

DRAWN	PROD ENG	QA	MKT	P/ECN#	DRAWING NO. 111-2213-0XX	AMPHENOL SPECTRA-STRIP 720 SHERMAN AVE TEL (203) 281-3200 HAMDEN CT 06514 FAX (203) 281-5872	Rev D
FITS 7/31/03	9/8/06			1052	TITLE: Spectra-Bond® Parallel		SHEET 1 of 1
					Conductor Cable		