


COMBINATION D-SUB CONTACTS

Coaxial contacts – Straight – PCB termination – 3 solder pins

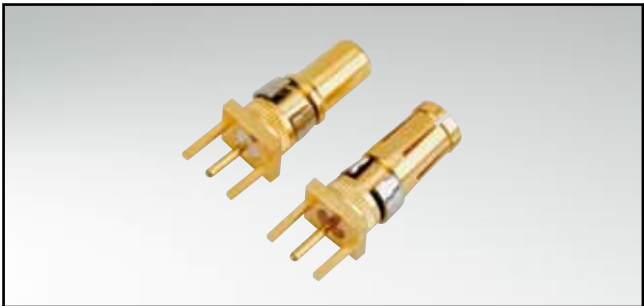


RoHS compliant – CSA listed, File No.: LR 115000-1 –UL listed, File No.: E 228329

- DESCRIPTION**
- 50 and 75 Ω design
 - Contact finishings:
 - .051 μ"/1.3 μm Au mating side inner conductor / .032 μ"/0.8 μm Au outer conductor
 - .008 μ"/0.2 μm Au mating side inner- and outer conductor
 - Quality class 1: 500 mating cycles (gold plated)


PRODUCT DRAWING

50 Ω version


Socket contact

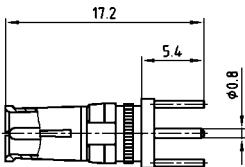

Installation dimension


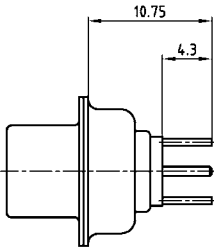


Plug contact

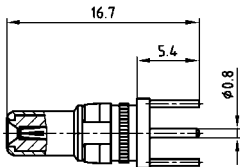


75 Ω version

Socket contact

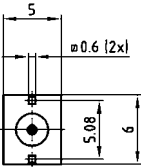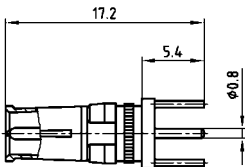

Plug contact

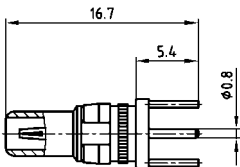

ORDER DATA

Socket contact .051 μ"/1.3 μm Au inner / .032 μ"/0.8 μm Au outer conductor		
Contact type	Termination*	Part Number
Socket 50 Ω	76	132 J 24019 X
Socket 75 Ω	86	132 J 34019 X

Plug contact .051 μ"/1.3 μm Au inner / .032 μ"/0.8 μm Au outer conductor		
Contact type	Termination*	Part Number
Plug 50 Ω	76	131 J 24019 X
Plug 75 Ω	86	131 J 34019 X

Socket contact .008 μ"/0.2 μm Au inner- and outer conductor		
Contact type	Termination*	Part Number
Socket 50 Ω	G7	132 A 24019 X
Socket 75 Ω	G8	132 A 34019 X

Plug contact .008 μ"/0.2 μm Au inner- and outer conductor		
Contact type	Termination*	Part Number
Plug 50 Ω	G7	131 A 24019 X
Plug 75 Ω	G8	131 A 34019 X

*Code use with part number creator