

CD 60X100 WH - Cable duct



3240631

<https://www.phoenixcontact.com/us/products/3240631>

Please be informed that the data shown in this PDF document is generated from our online catalog. Please find the complete data in the user documentation. Our general terms of use for downloads are valid.



Cable duct for installation and mounting in control cabinets, white, comprising upper part and mounting base, width: 60 mm, height: 100 mm, length: 2000 mm

Your advantages

- Predetermined breaking point enables tool-free, burr-free removal of bars
- Thanks to its leverage and special cutting geometry, the PPS CD cable duct cutter enables easy, burr-free cutting with minimum effort
- Easy, burr-free cutting with minimum effort using the CUTFOX-CD cable duct cutter
- The wide, diagonal heads of the cable duct bars make it easy to fit the cover and hold it securely in place
- Installed conductors are securely held in place by means of wire retaining clips that can be snapped onto bars on the side
- Plastic body-bound rivets enable easy fixing of cable ducts using the rivet setting tool

Commercial data

Item number	3240631
Packing unit	8 pc
Minimum order quantity	8 pc
Sales key	BE74
Product key	BE7433
Catalog page	Page 581 (C-3-2019)
GTIN	4046356629577
Weight per piece (including packing)	1,937 g
Weight per piece (excluding packing)	1,937 g
Customs tariff number	39259020
Country of origin	DE

CD 60X100 WH - Cable duct

3240631

<https://www.phoenixcontact.com/us/products/3240631>



Technical data


Product properties

Product type	Wiring duct
--------------	-------------

Connection data

Nominal cross section	4239 mm ²
-----------------------	----------------------

Dimensions

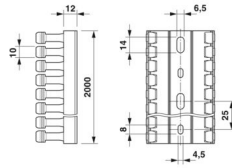Dimensional drawing	
Width	60 mm
Height	2000 mm
Depth	100 mm
Length	2000 mm

Material specifications

Color	white
Material	PVC
Flammability rating according to UL 94	V0
Components	Lead-free

Cable/line

Halogen-free	no
--------------	----

Environmental and real-life conditions

Ambient conditions

Ambient temperature (operation)	-5 °C ... 60 °C
---------------------------------	-----------------

CD 60X100 WH - Cable duct


3240631

<https://www.phoenixcontact.com/us/products/3240631>



Drawings

Dimensional drawing

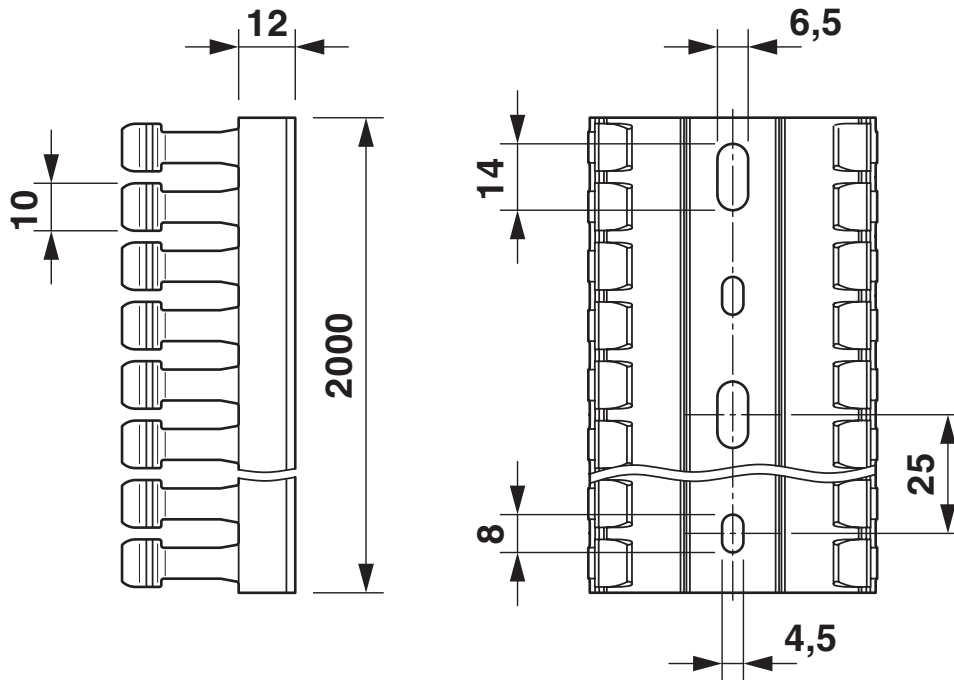

Base perforation according to DIN EN 50085

CD 60X100 WH - Cable duct

3240631

<https://www.phoenixcontact.com/us/products/3240631>



Approvals

To download certificates, visit the product detail page: <https://www.phoenixcontact.com/us/products/3240631>



VDE Zeichengenehmigung

Approval ID: 40058456



cULus Recognized

Approval ID: E328576



cCSAus

Approval ID: 80202282

CD 60X100 WH - Cable duct



3240631

<https://www.phoenixcontact.com/us/products/3240631>

Classifications

ECLASS

ECLASS-11.0	27400703
ECLASS-12.0	27400703
ECLASS-13.0	27400703

ETIM

ETIM 9.0	EC000012
----------	----------

UNSPSC

UNSPSC 21.0	39131700
-------------	----------

CD 60X100 WH - Cable duct

3240631

<https://www.phoenixcontact.com/us/products/3240631>



Environmental product compliance

EU RoHS

Fulfills EU RoHS substance requirements	Yes, No exemptions
---	--------------------

China RoHS

Environment friendly use period (EFUP)	EFUP-E
	No hazardous substances above the limits

EU REACH SVHC

REACH candidate substance (CAS No.)	No substance above 0.1 wt%
-------------------------------------	----------------------------

CD 60X100 WH - Cable duct

3240631

<https://www.phoenixcontact.com/us/products/3240631>



Accessories

RVT-PA 4 - Fastening clip

3240498

<https://www.phoenixcontact.com/us/products/3240498>



Plastic body-bound rivet, for hole diameter of 4 mm and a material thickness of 1.5 ... 6 mm

RVT-PA 6 - Fastening clip

3240499

<https://www.phoenixcontact.com/us/products/3240499>



Plastic body-bound rivet, for hole diameter of 6 mm and a material thickness of 1.5 ... 6 mm

CD 60X100 WH - Cable duct

3240631

<https://www.phoenixcontact.com/us/products/3240631>



CD COVER 60 WH - Cover profile

3240648

<https://www.phoenixcontact.com/us/products/3240648>



Cover for cable duct, white, width: 60 mm, length: 2000 mm

UNIFOX-RVT P 4 - Tool

1212478

<https://www.phoenixcontact.com/us/products/1212478>



Rivet setting tool, for use with RVT-PA 4 plastic body-bound rivets

CD 60X100 WH - Cable duct

3240631

<https://www.phoenixcontact.com/us/products/3240631>



UNIFOX-RVT P 6 - Tool

1212509

<https://www.phoenixcontact.com/us/products/1212509>



Rivet setting tool, for use with RVT-PA 6 plastic body-bound rivets

Phoenix Contact 2024 © - all rights reserved

<https://www.phoenixcontact.com>

Phoenix Contact USA
586 Fulling Mill Road
Middletown, PA 17057, United States
(+717) 944-1300
info@phoenixcon.com