



Part Number: D4I1840



Electrical Specifications

Frequency Range (GHz):	18.0	-	40.0
Isolation (dB):	18	MIN	
Insertion Loss (dB):	4.2	MAX	
VSWR:	2.1:1	MIN	
Forward Power (W):	5	AVG	
	30	PK	
Reflective Power (W):	2	AVG	


Mechanical/Environmental Specifications

Connector Type:	K (2.92mm)
Connector Body:	Passivated stainless steel
Connector Pin:	Gold plated copper
Load Body:	Brass
Magnetic Shunt:	Nickel plated CRS
Operational Temp:	-20°C to +65°C
Weight (oz)	2.0 MAX

D4I1840 Dimensions

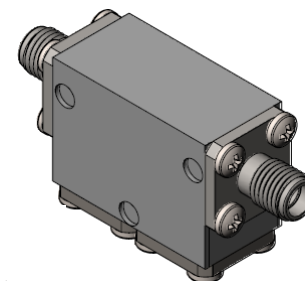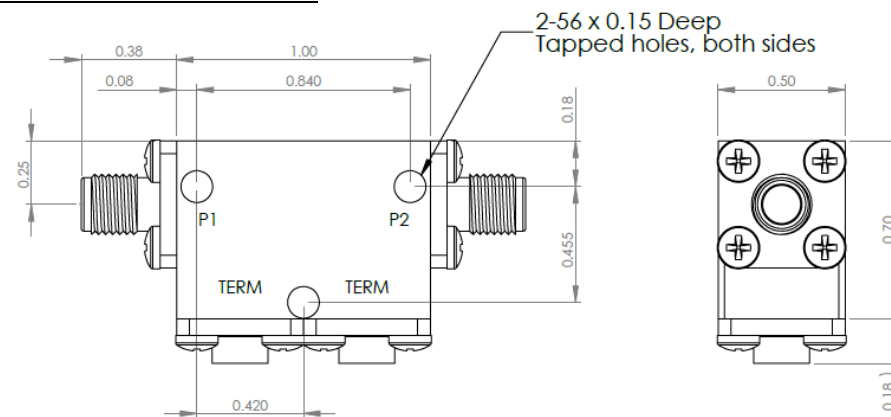

D4I1840-3 Dimensions

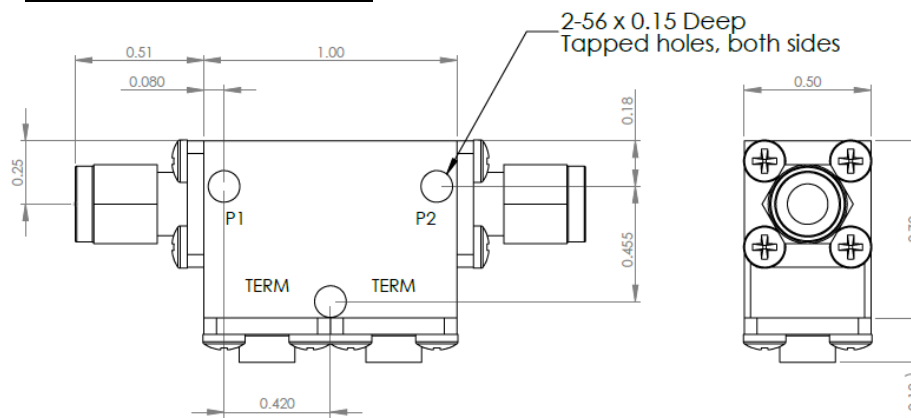

Dimensions are in inches
Tolerance
XX ±0.03
XXX ±0.010

Type of Device	PN Suffix	Connector Configuration Input / Output	PN Example
Single and Dual Junction Isolator, 2-Port Device Input / Output	N/A	Female / Female	D4I1840
	-1	Male / Female	D4I1840-1
	-2	Female / Male	D4I1840-2
	-3	Male / Male	D4I1840-3



MEASURED DATA

Part Number: D4I1840, +25°C

