




Part Number : [732510930](#)

Product Description : SMA Jack, Straight, Bulkhead, Crimp, RG-174, RG-188 and RG-316 Cable, with Shrink Tube, Brass Body, Gold (Au) Plated, Bag, 50 Ohms

Series Number : 73251

Status : Active

Product Category : RF / Coaxial Connectors

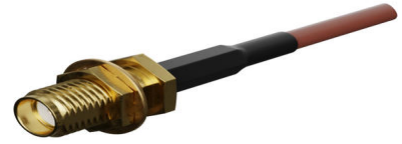

Documents and Resources

Drawings

[732510930 sd.pdf](#)

[895420300-000.pdf](#)

3D Models and Design Files


[STEP AP242](#)

[SOLIDWORKS](#)

[Creo](#)

Product Environment Compliance

Compliance

GADSL/IMDS	Compliant with Exemption 44; 3; 34; 33
China RoHS	 per SJ/T 11365-2006
EU ELV	Not Relevant
Low-Halogen Status	Low-Halogen per IEC 61249-2-21
REACH SVHC	Contains Lead per D(2025)4165-DC (25 June 2025)
EU RoHS	Compliant with Exemption 6(c) per EU 2015/863

Compliance Statements

- EU RoHS
- REACH SVHC
- Low-Halogen

Industry Documents

- IPC 1752A Class C
- IPC 1752A Class D
- Molex Product Compliance Declaration
- IEC-62474
- chemSHERPA (xml)

Substances of Interest

- PFAS

EU RoHS Certificate of Compliance

Additional Product Compliance Information

Part Details

General

Status	Active
Category	RF / Coaxial Connectors
Series	73251
Description	SMA Jack, Straight, Bulkhead, Crimp, RG-174, RG-188 and RG-316 Cable, with Shrink Tube, Brass Body, Gold (Au) Plated, Bag, 50 Ohms
Application	RF
Product Name	SMA
Style	Cable
Type	Subminiature
UPC	756054358825

Electrical

Frequency	18 GHz
Impedance	50Ω
Power / Voltage	VOLTAGE: 500 Vrms@Sea Level

Physical

Cable Attachment	Crimp
Gender	Jack
Keying to Mating Part	N/A
Net Weight	3.396/g

Orientation	Straight
Packaging Type	Bag
Panel Mount	Yes
Panel Mount Method	Bulkhead
PCB Mounting	N/A
Reverse Polar	No
Wire/Cable Type	LMR-100, RG-174, RG-188, RG-316

Solder Process Data

Lead-Free Process Capability	N/A
------------------------------	-----

This document was generated on Dec 26, 2025