


COIL: @ 25°C  
 RESISTANCE 400 OHMS ± 10%  
 NOMINAL VOLTAGE 26.5 VDC  
 MUST OPERATE 13.0 VDC  
 MUST RELEASE 10.1 VDC MAX

ENVIRONMENT:  
 VIBRATION 10 CPS TO 2000 CPS @ 15 g's  
 SHOCK 100 g's 6 MS. DURATION  
 TEMPERATURE -65 °C TO +125 °C

NOTES: MEETS MIL-R-5757  
OPERATE & RELEASE TIME 10 MS MAX.  
CONTACT BOUNCE 1 MS MAX.

CUSTOMER DATA SHEET

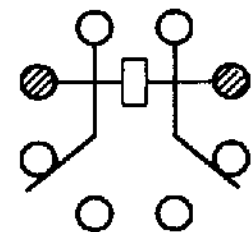

CONTACT RATING: 2 AMPS 28 VDC  
RESISTIVE 100,000 OPERATIONS

DR. R.B. 5/17/94 CK.5/17/94 JMB

**COMMUNICATIONS INSTRUMENTS, INC.**

CUST. QPL  
 CUST. NO. M5757/8-002

TYPE '02' RELAY

02A312HC2-0030