


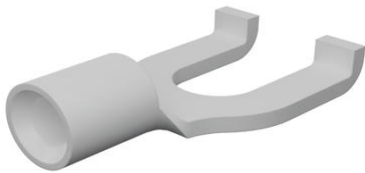

Part Number : [191180054](#)
Product Description : Krimptite Flanged Spade
Tongue Terminal for 16-14 AWG Wire, Stud Size 6
(M3.5), Carton
Series Number : 19118
Status : Active
Product Category : Ring and Spade Terminals
Engineering Part Number : BB-116-06



Documents and Resources

Drawings

[191180054 sd.pdf](#)
[PK-19902-001-001.pdf](#)

Specifications

[PS-19902-013-001.pdf](#)

Product Environment Compliance

Compliance

GADSL/IMDS	Not Relevant
China RoHS	 per SJ/T 11365-2006
EU ELV	Not Relevant
Low-Halogen Status	Low-Halogen per IEC 61249-2-21
REACH SVHC	Not Contained per D(2025)7771-DC (04 Feb 2026)
EU RoHS	Compliant per EU 2015/863

Compliance Statements

- EU RoHS
- REACH SVHC
- Low-Halogen

Industry Documents

- IPC 1752A Class C
- IPC 1752A Class D

- Molex Product Compliance Declaration
- IEC-62474
- chemSHERPA (xml)

Substances of Interest

- PFAS

EU RoHS Certificate of Compliance

Additional Product Compliance Information

Part Details

General

Status	Active
Category	Ring and Spade Terminals
Series	19118
Description	Krimptite Flanged Spade Tongue Terminal for 16-14 AWG Wire, Stud Size 6 (M3.5), Carton
Product Name	Krimptite
Style	Spade
Type	Spade Connector, Metric Spade Connector
UPC	800755082623

Agency

CSA	LR18689
UL	E32244

Physical

Barrel Type	Closed
Insulation	None
Material - Plating Mating	Tin
Net Weight	0.596/g
Packaging Type	Carton
Plating min - Mating	4.064µm
Plating min - Termination	4.064µm
Stud Size	6 (M3.5)
Wire Size (AWG)	14, 16

Wire Size mm ²	1.00-2.50
---------------------------	-----------

Application Tooling

This document was generated on Apr 29, 2026