


Specification Sheet

Part Number: 251-30309

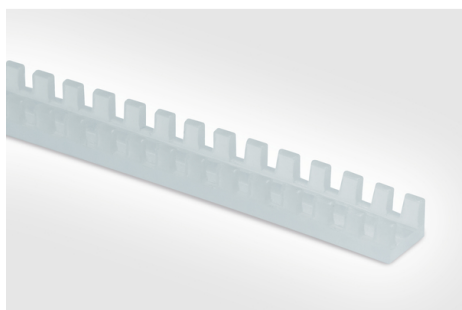

Can be cut to length with scissors, eliminating waste and keeping stock to a minimum.

Available in 9 sizes, for thicknesses from .016" to .512", insuring proper fit.

Grommet, Panel Thickness 0.083"-0.130", PTFE, Natural, 9.7ft/pkg

Article Number 251-30309

Type G51TC

Color Natural (NA)

Quantity Per pack

Product Description HellermannTyton's Flexiform grommet is a unique, continuous wire protection product which fits easily in all shapes and sizes of holes without the aid of tools or adhesives. Flexiform grommet can be used on any type of material including wood, steel, aluminum, plexiglass, and glass.

Short Description Grommet, Panel Thickness 0.083"-0.130", PTFE, Natural, 9.7ft/pkg

Global Part Name G51TC-PTFE-NA

Length L (Imperial)	9.7
Variant	Open
Width W (Imperial)	0.224
Width W (Metric)	5.7
Height H (Imperial)	0.169
Height H (Metric)	4.3
Panel Thickness Min (Imperial)	0.08
Panel Thickness Max (Imperial)	0.13
Panel Thickness Min (Metric)	2.1
Panel Thickness Max (Metric)	3.3
Material	Polytetrafluoroethylene (PTFE)
Material Shortcut	PTFE
US MIL SPEC	MS21266-3T
Flammability	UL 94 V-0
Halogen Free	No

UV Resistant (Yes/No)	No
Use Conditions	For Indoor and Outdoor Use
Operating Temperature	-76°F to +500°F (-60°C to +260°C)
Reach Compliant (Article 33)	Yes
ROHS Compliant	Yes
Package Quantity (Imperial)	9.7
Package Quantity (Metric)	3
Customs Number	3926909988

7930 N. Faulkner Road, Milwaukee, WI 53224

Phone: (800) 537-1512 | Email: corp@htamericas.com

© 2026 HellermannTyton. All Rights Reserved.

[Contact Us](#) [RoHS/WEEE Compliance](#) [Privacy Policy](#) [Cookie Policy](#) [Terms and Conditions](#)