

CATEGORIES

All

For more information or to request assistance, please contact sales@precidip.com

[« Back to search results](#)

YOUR SELECTED PRODUCT

Screw-machined Contacts

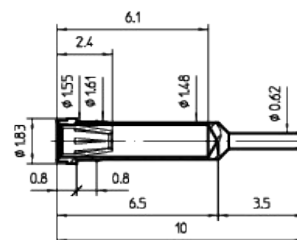
01304

Socket contacts

For other versions than the listed available standard types, please contact PRECI-DIP

SPECIFICATIONS:

- Socket contact with solder tail
- Press-in mount into dia 1.55 mm hole
 - Materials: body brass, contact clip BeCu
 - Electrical contact resistance max. 10 milliohms
 - Mechanical life min. 500 cycles

 Metric

AVAILABLE STANDARD TYPES

Ordering Part Number		Plating Body	Plating Clip	Insertion	Extraction	Dia.Gauge	Max Current
01304-83-4710	RoHS	5µm Sn	0.75µm Au	1.70 N	0.70 N	0.76 mm	4.5 A
01304-87-4710	RoHS	5µm Sn	Flash Au	1.70 N	0.70 N	0.76 mm	4.5 A

CAD CATALOG

Literature
Catalog
CAD catalog

ABOUT PRECI-DIP

Career
Contact
Events

OTHER INFO

Feedback
Legal disclaimer
Cross references

NEWSLETTER

Stay informed!

Company

Last name, first name

Email

subscription

This website is using cookies for statistics, site optimization and retargeting purposes. You consent to our cookies if you continue to use this website. [Read more here.](#)

powered by

arion

Accept