

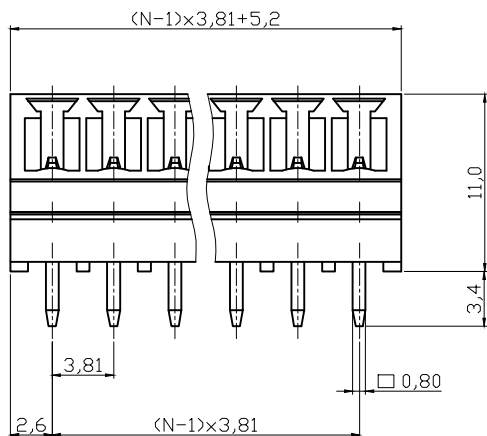
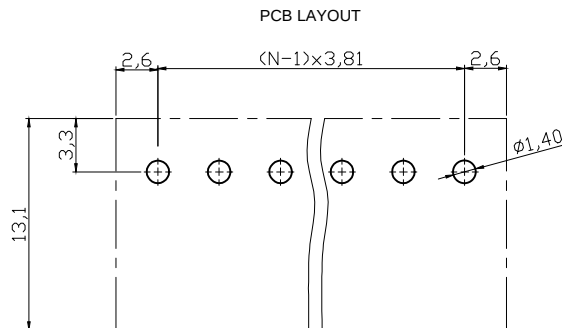


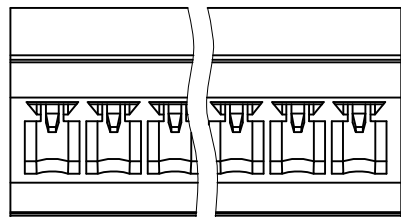

N= NUMBER OF CONTACTS

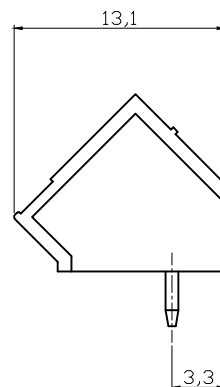

Material
Contact Pin: Brass
Insulator (housing): Thermoplastic (UL94V-0), Green
Surface of solder tail: Tin plated

Electrical cULus / VDE
Voltage rating: 300VAC / 300VAC
Current rating: 8A / 10A
Wire range:
Solid wire(AWG):
Wire strip length:
Withstanding Voltage: 1.6KV / 2.5KV
Operating temperature: -30°C to +105°C
Soldering temperature: 250°C±10°C/5 Sec
Safety Approval:

RoHS compliant

Unit:mm



File No.: E349947

Scale	1:1						Date	Name	Customer-No.
TOLERANCE						Drawn	10.12.2009	Dean	
X.	±0.50					Approved	01.04.2016	Joanna	ASSMANN WSW-No.
X.X	±0.30								A-TB381-VKxx
X.XX	±0.10								Drawing-No.
DIM	TOL	②	Add UL	01.04.2016	Joanna	ASSMANN WSW components		ASS 3840 CO	rev02
X.°	±1°	①	Drawn	10.12.2009	Dean			Replace	Sheet
Angle	TOL	Id.	Modification	Date	Name				

1

2

3

4

5

6

7