
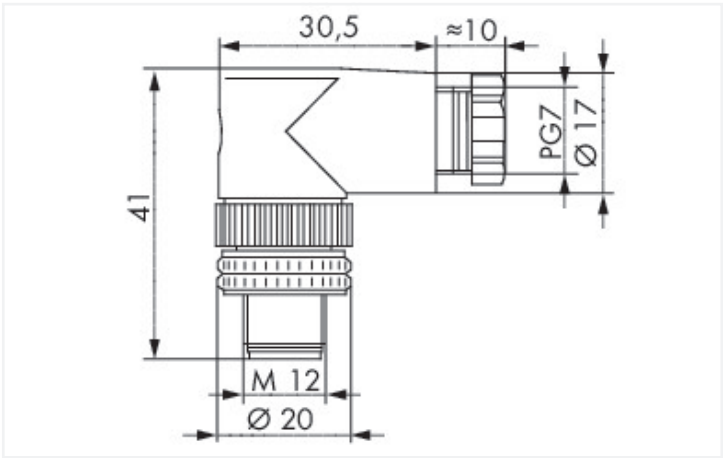


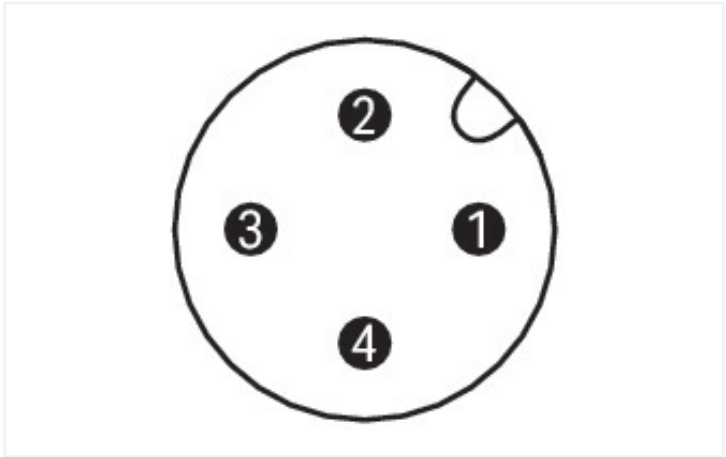

Dimensions in mm

Technical data	
Connection type	M12 plug
Pole number	4
Cable connection direction to mating direction	90 °
Connector interface coding (cable/adapter) 1 1	A-coded
Contact resistance	≤3 mΩ

Connection data	
Connection type	Screw clamp technology
Solid conductor	0.25 ... 0.75 mm²

Mechanical data	
Connectable sheathed cable diameter	4 ... 6 mm
Housing material	Polybutylene terephthalate (PBT)
Contact material	CuZn
Contact Plating	Gold
Seal material	Sealing ring: neoprene
Mating cycles (max.)	100
Weight	26 g



Environmental requirements		
Ambient temperature (operation)		-25 ... +85 °C
Protection type		IP67
Note on protection type		in locked state
Pollution degree		3
Fire load		0 MJ

Commercial data		
PU (SPU)		5 pcs
Packaging type		Box
Country of origin		HU
GTIN		4044918977432
Customs tariff number		85366990990

Product Classification		
UNSPSC		39121413
eCl@ss 10.0		27-24-26-92
eCl@ss 9.0		27-24-26-92
ETIM 9.0		EC002584
ETIM 8.0		EC002584
ECCN		NO US CLASSIFICATION

Environmental Product Compliance		
RoHS Compliance Status		Compliant, No Exemption

Downloads		
Environmental Product Compliance		
Compliance Search		
Environmental Product Compliance 756-9204/040-000		

Documentation				
System Description			Bid Text	
IP67 Cables and Plug-gable Connectors	pdf 157.80 KB		756-9204/040-000	19.02.2019
			xml 2.69 KB	
			756-9204/040-000	20.09.2017
			doc 24.00 KB	



CAD/CAE-Data	
CAE data	
WSCAD Universe 756-9204/040-000	