


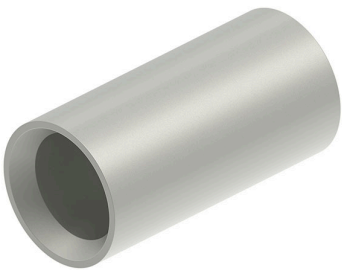

Part Number : [192050012](#)  
Product Description : VersaKrimp Butt Splice  
for 3/0 AWG Wire  
Series Number : 19205  
Status : Active  
Product Category : Splices  
Engineering Number : K-393



---

## Documents & Resources

### Drawings

[192050012\\_sd.pdf](#)

### 3D Models and Design Files

[192050012\\_stp.zip](#)

### Specifications

[PS-19902-011-001.pdf](#)

[PS-19902-013-001.pdf](#)

---

## Product Environment Compliance

### Compliance

GADSL/IMDS	Not Relevant
China RoHS	Not Relevant
EU ELV	Not Relevant
Low-Halogen Status	Low-Halogen per IEC 61249-2-21
REACH SVHC	Not Contained per D(2020)4578-DC (25 June 2020)
EU RoHS	Compliant per EU 2015/863

### [Multiple Part Product Compliance Statements](#)

- Eu RoHS
- REACH SVHC
- Low-Halogen

## Multiple Part Industry Compliance Documents

- IPC 1752A Class C
- IPC 1752A Class D
- Molex Product Compliance Declaration
- IEC-62474
- chemSHERPA (xml)

## EU RoHS Certificate of Compliance

---

### Part Details

#### General

Status	Active
Category	Splices
Series	19205
Description	VersaKrimp Butt Splice for 3/0 AWG Wire
Product Name	Butt,VersaKrimp
UPC	800755060935

#### Physical

Barrel Type	Closed - Brazed
Insulation	None
Material - Metal	Copper
Material - Plating Mating	Tin
Material - Plating Termination	Tin
Net Weight	39.640/g
Packaging Type	Bag
Wire Size (AWG)	3/0

---

### Application Tooling

#### Global

Description	Part Number
Die Set (Large) for the HHLS Hydraulic Crimper	<u>192900028</u>
Manual Tool for Crimping Non-insulated 8 AWG thru 4/0 Terminals	<u>192940008</u>

Putt Pump Dieless Head Crimper, For Insulated and Non-Insulated Terminals and Splices	<u>638162000</u>
---	------------------

---

This document was generated on Mar 02, 2025