




Color: ■ black

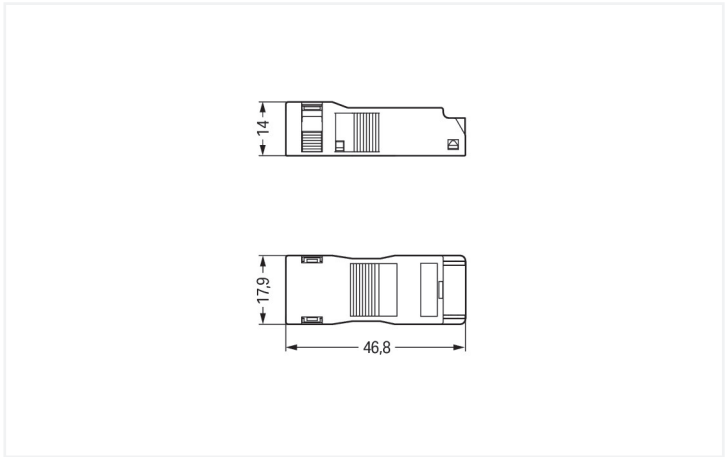

Dimensions in mm

Strain relief housing WINSTA® MINI 3-pole

When using the strain relief housing from the WINSTA® MINI product line, straightforward installation is guaranteed. You can rely on the quality of WINSTA® components from WAGO for your electrical installation accessories too. Thanks to its particularly small dimensions, our WINSTA® MINI Pluggable Connection System with Push-in CAGE CLAMP® spring pressure connection technology is very suitable in very restricted spaces, i.e., for connections when very little room is available. The strip length is 40 mm.

Push-in CAGE CLAMP® spring pressure connection technology – pluggable installation instead of laborious screw connections!

The WINSTA® Pluggable Connection System allows pluggable electrical installation. This significantly reduces the need for servicing and lowers costs. Take advantage of the pluggable version of our maintenance-free spring pressure connection technology too! Plan your installation with with protection against mismating from WAGO.

- compact design for conductors with a cross-section up to 1.5 mm²
- convenient installation and commissioning

Connection data	
Connection 1	
Pole number	3
Connectable sheathed cable diameter	4.5 ... 10 mm
Strip length (outer insulation)	40 mm

Physical data	
Pin spacing	4.4 mm / 0.173 inches
Width	17.9 mm / 0.705 inches
Height	14 mm / 0.551 inches
Depth	46.8 mm / 1.843 inches



Material data		
Note (material data)		Information on material specifications can be found here
Color	black	
Insulation material (main housing)	Polyamide (PA66)	
Flammability class per UL94	V0	
Fire load	0.134 MJ	
Weight	3.5 g	

Environmental requirements		
Processing temperature	-5 ... +40 °C	
Continuous operating temperature	-35 ... +85 °C	
Note on continuous operating temperature	Insulating parts for temperatures ≤ 105 °C	

Commercial data		
Product Group	20 (Winsta)	
PU (SPU)	50 pcs	
Packaging type	Box	
Country of origin	DE	
GTIN	4045454233327	
Customs tariff number	39269097900	

Product Classification		
UNSPSC	39121421	
eCl@ss 10.0	27-44-06-92	
eCl@ss 9.0	27-44-06-92	
ETIM 9.0	EC002863	
ETIM 8.0	EC002863	
ECCN	NO US CLASSIFICATION	

Environmental Product Compliance		
RoHS Compliance Status	Compliant,No Exemption	

Approvals / Certificates

General approvals



Approval	Standard	Certificate Name
cURus Underwriters Laboratories Inc.	UL 1977	E45171



Downloads

Environmental Product Compliance

Compliance Search

Environmental Product Compliance 890-503

↓

Documentation				
Bid Text				
890-503	19.02.2019	xml	2.75 KB	↓
890-503	24.11.2014	doc	23.50 KB	↓

CAD/CAE-Data

CAD data

2D/3D Models 890-503

↓

CAE data

EPLAN Data Portal 890-503

↓

WSCAD Universe 890-503

↓

ZUKEN Portal 890-503

↓

1 Compatible Products

1.1 Optional Accessories

1.1.1 Shield termination

1.1.1.1 Shield termination



Item No.: 890-523
Shield connecting plate; 3-pole; for sockets and plugs; silver-colored