



AMRU00040412R22MA1

Search by :

- Part Number ↗
- Characteristics ↗
- Cross reference ↗




MP

Auto

Closed Magnetic Circuit Type
Molding Processing & for Ultra High Current

- Series Pdf
- RoHSREACHCoC

Product detail		
L(mm) ±	4.2±0.25	
W(mm) ±	4.7±0.25	
T(mm) ±	1.2Max.	
Inductance(uH)	0.22	
Tolerance(±%)	20	
Test Frequency	100kHz,0.5V	
RDC(Ω)Max	0.012	
Isat(A)Typ	15	
Irms(A)Typ	8.5	
Operating Temperature	-40℃~125℃	

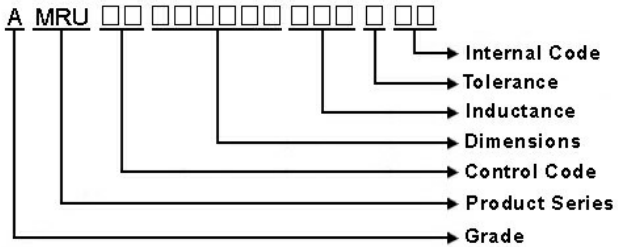

Products

- Power Inductor
- EMI-Common Mode Choke
- EMI-Bead
- RF-Signal Inductor
- RF-Passives/Antennas
- LAN Transformer
- Resistor & Current Sensor

Applications

- Automotive
- Industrial
- Server/DataCenter
- Communication
- Mobile and Tablet
- Computer/Laptop
- Consumer

Design Tools

- Simulation Tool
- Product Search Engine
- E-Catalogue

About Us

- Corporate Overview
- Corporate Milestones
- Core Technology
- Certificates & Awards
- Quality and Social Responsibility

Investor

- Financial Information
- Corporate governance
- Stakeholder Contacts

[Media Center](#)
[New Products](#)
[Events](#)
[Product Notices](#)

Contact Us

[Contact Info](#)
[Contact Form](#)
[Join Chilisín](#)

[Terms of Use](#)
[Privacy policy](#)
[Sitemap](#)



Inductor



Resistor



Powder

Copyrights © 2018. Chilisín. All rights reserved.