

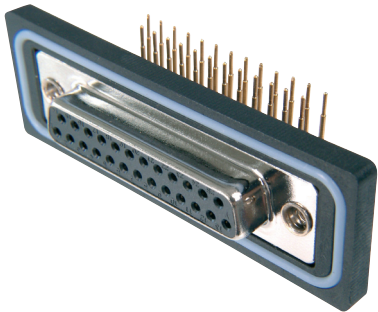


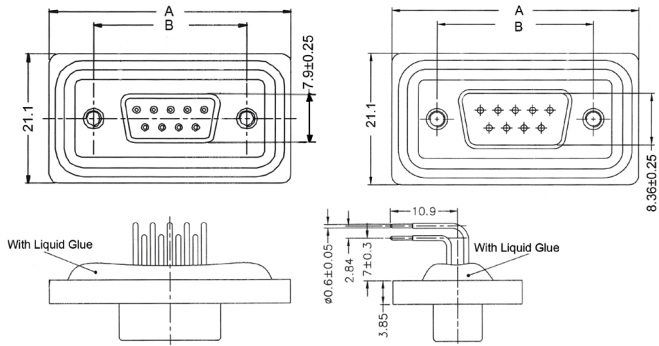

Isolierkörpermaterial
PBT, UL94V-0
Kontaktmaterial
Messing
Kontaktoberfläche
Ni, Au
Kontaktwiderstand
20mΩ max
Isolationswiderstand
500MΩ min
Strombelastbarkeit
5A
Betriebstemperatur
-40°C - +105°C
Betriebsspannung
250V AC
Prüfspannung
1000V AC
Verpackung
Blisterverpackung

Insulator material
PBT, UL94V-0
Contact material
Brass
Plating
Ni, Au
Contact resistance
20mΩ max
Insulation resistance
500MΩ min
Current rating
5A
Operating temperature
-40°C - +105°C
Operating voltage
250V AC
Test voltage
1000V AC
Packing
Tray packing

Dimensions				
No. of contacts	A	B	C	D
09	39.4	25.0	28.20	20.0
15	47.8	33.3	36.50	28.0
25	64.5	47.1	51.00	41.5

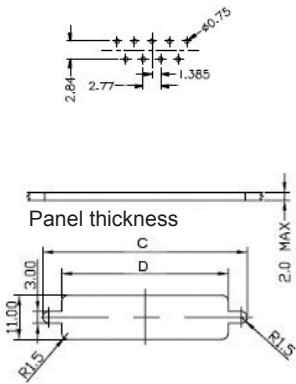

Bestellcode / Ordercode

Kontaktart
F - Buchse
S - Stecker

Polzahl
09 / 15 / 25
WP - IP67

Contact style
F - Female
S - Male

No. of contacts
09 / 15 / 25
WP - IP67

A - D x xx AA - WP

Bitte „x“ durch die geeignete Option ersetzen
Please replace „x“ with appropriate option