


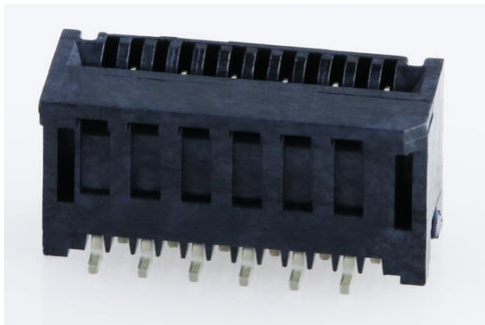

**Part Number :** [781271210](#)  
**Product Description :** 0.50mm Pitch Easy-On FFC/  
FPC Connector, Surface Mount, Vertical, Non-ZIF,  
Reverse Footprint, Tin Bismuth Plating, Long Terminal  
Type, Black, 12 Circuits  
**Series Number :** 78127  
**Status :** Active  
**Product Category :** FFC / FPC Connectors



## Documents & Resources

### Drawings

[781271210 sd.pdf](#)

### 3D Models and Design Files

[STEP AP242](#)

[SOLIDWORKS](#)

[Creo](#)

[Symbol and Footprint \(Multi-Format\)](#)


### Specifications

[781279200-201.pdf](#)

[781190001-000.pdf](#)

## Product Environment Compliance

### Compliance

GADSL/IMDS	Compliant with Exemption 44; 33
China RoHS	 per SJ/T 11365-2006
EU ELV	Not Relevant
Low-Halogen Status	Low-Halogen per IEC 61249-2-21
REACH SVHC	Not Contained per D(2025)4165-DC (25 June 2025)
EU RoHS	Compliant per EU 2015/863

[Compliance Statements](#)

- EU RoHS
- REACH SVHC
- Low-Halogen

#### Industry Documents

- IPC 1752A Class C
- IPC 1752A Class D
- Molex Product Compliance Declaration
- IEC-62474
- chemSHERPA (xml)

#### Substances of Interest

- PFAS

#### EU RoHS Certificate of Compliance

#### Additional Product Compliance Information

## Part Details

### General

Status	Active
Category	FFC / FPC Connectors
Series	78127
Description	0.50mm Pitch Easy-On FFC/FPC Connector, Surface Mount, Vertical, Non-ZIF, Reverse Footprint, Tin Bismuth Plating, Long Terminal Type, Black, 12 Circuits
Product Name	Easy-On
UPC	889056671286

### Electrical

Current - Maximum per Contact	0.5A
Voltage - Maximum	50V

### Physical

Actuator Type	Non-ZIF
Circuits (Loaded)	12
Color - Resin	Black
Contact Position	N/A
Durability (mating cycles max)	10

Mated Height	4.10mm
Material - Metal	Phosphor Bronze
Material - Plating Mating	Tin-Bismuth
Material - Plating Termination	Tin-Bismuth
Material - Resin	Liquid Crystal Polymer
Net Weight	136.010/mg
Orientation	Vertical
Packaging Type	Embossed Tape on Reel
PCB Locator	No
PCB Mounting	Surface Mount
PCB Retention	None
Pitch - Mating Interface	0.50mm
Pitch - Termination Interface	0.50mm
Plating min - Mating	1.000µm
Polarized to PCB	No
Stackable	No
Temperature Range - Operating	-40° to +85°C
Wire/Cable Type	FFC/FPC

---

## Mates With / Use With

### Mates with Part(s)

Description	Part Number
0.50mm Pitch Premo-Flex FFC Jumpers	<u>15166</u>
0.50mm Pitch Premo-Flex FFC Jumpers	<u>15266</u>
0.50mm Pitch Premo-Flex FFC Jumpers	<u>98266</u>
0.50mm Pitch Premo-Flex FFC Jumpers	<u>15366</u>

---

This document was generated on Sep 22, 2025